


Part Number: 334

Type	Size	Rating	Description
Incandescent	T6	28V 40mA	T-1 ³ / ₄ Midget Groove Lamp

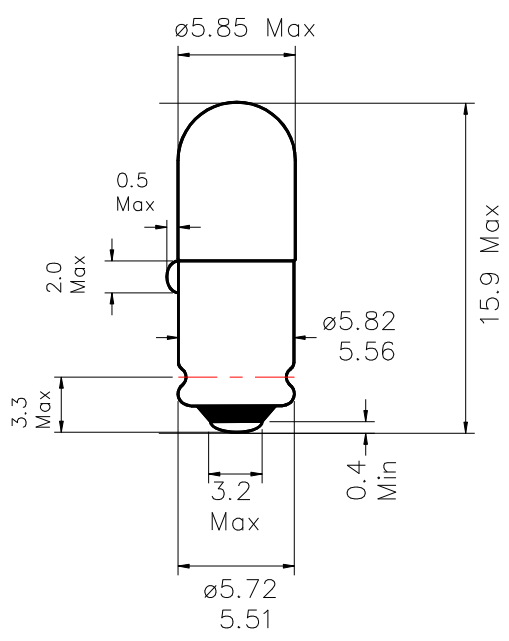

Dimensions in millimetres

TEST VOLTS	CURRENT (mA)			LIGHT OUTPUT (Lm)			LIFE Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
28	36	40	44	3.2	4.3	5.3	4,000

Notes:

- 1 Base Type Nickel plated S5.7s base in accordance with BS EN 60061-1
- 2 Filament Shape C-2F
- 3 Lamp Marking **CM334 28V 40mA**
- 4 Environmental RoHS & REACH SVHC compliant