


speed II




- > **Designed and engineered by Wiha Germany**
- > **Made in Germany**
set contains some global components
- > **Only compatible with Wiha SlimLine Blades**
for optimal safety and function
- > **Each SlimLine Blade is individually tested**
to 10,000V AC and rated to 1,000V AC
- > **Two power levels 0.4 Nm - 1.0 Nm / 3.5 in/lbs - 8.8 in/lbs**
for improved range of performance
- > **Torque-ratcheting function**
for hand-finishing fasteners and damage prevention
- > **Integrated ring-light**
for low-light work environments



E-SCREWDRIVER speedE® II ELECTRIC

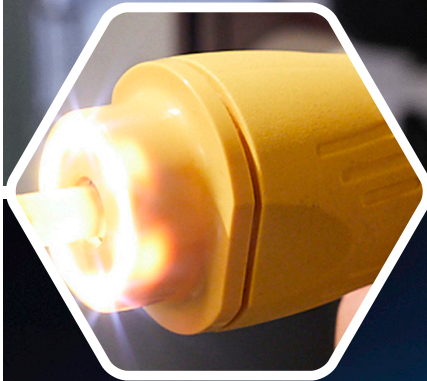

LED Light
glows after releasing the switch,
blinks when battery is low

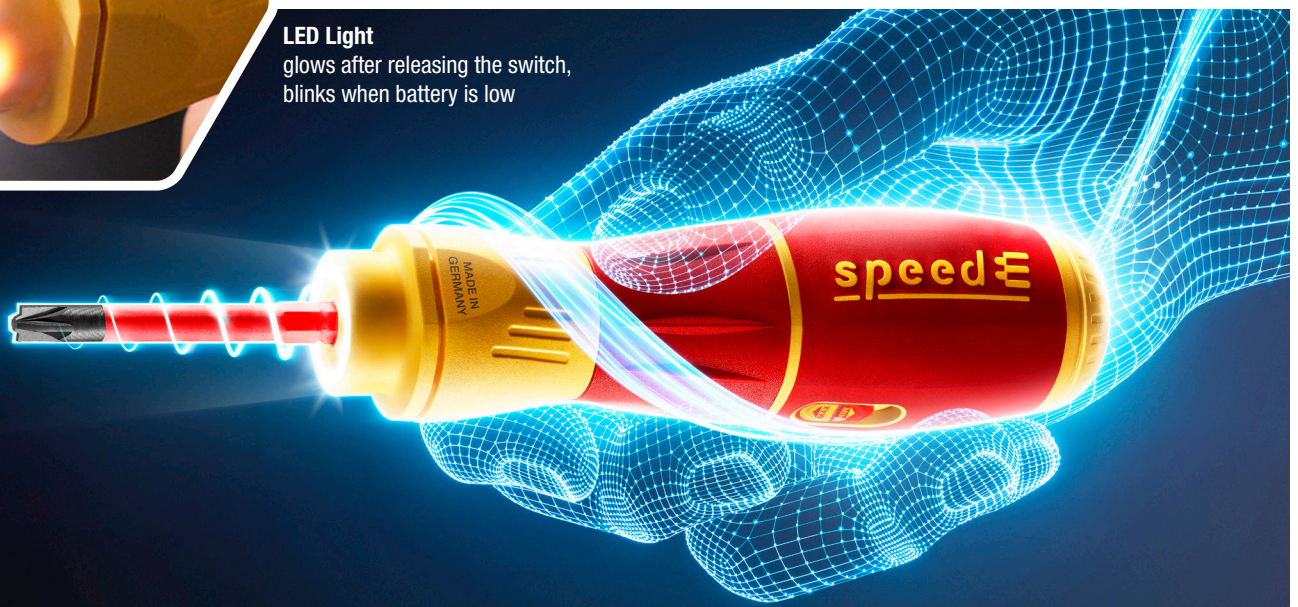

speedE®II Electric Screwdriver



The Wiha Insulated speedE®II electric screwdriver is faster, stronger, and more efficient than ever. The new speedE®II now features two power levels (0.4 Nm - 1.0 Nm or 3.5 in-lbs - 8.8 in-lbs) for an improved range of performance. Upon reaching the torque capacity, simply continue turning fastener by hand using the built-in ratcheting function to reach the desired tightness and thereby decreasing risk of equipment damage. Change power levels by toggling a switch integrated into a form-fit handle that delivers comfort and control and features a ring light for low-light work environments. Comes with rechargeable lithium-ion batteries for driving up to 800 fasteners per charge—USB charger with plug adapter is included.

SKU: 32490

Details

- > **VDE Certified and meet EN/IEC 60900 testing standards**
for protection against arc flash explosion
- > **ASTM F1505 standard specifications**
for insulated and insulating hand tools
- > **NFPA-70E standards**
for electrical safety on the job site
- > **CSA testing benchmarks**
for safety and performance
- > **Rechargeable Lithium-Ion Batteries**
for driving up to 800 fasteners per charge
- > **Charger is a USB connection with plug adapter**
for versatile charging capabilities
- > **Backed by the Wiha No Hassle Guarantee**



switch to a new power level of 1.0 Nm, speedE®II is now also the ideal tool for screw driving tasks requiring greater force



Slotted 3.5 | 5.5mm



Phillips #1 | #2



Square #1 | #2





Terminal Xeno #1 | #2

Weight (lbs)	2.14000
RoHS Compliant	Yes
Head Type	slotted, phillips, square terminal xeno
Pieces In Set	13
UPC	084705324906
UNSPSC	27112710



*speedE electric screwdriver is only insulated when used with Wiha SlimLine blades

E-SCREWDRIVER speedE®II ELECTRIC

speedE®II that works for you

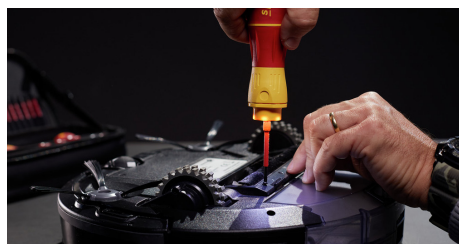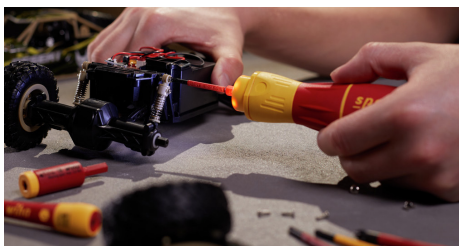

speedE®II Electric 13 Piece Set

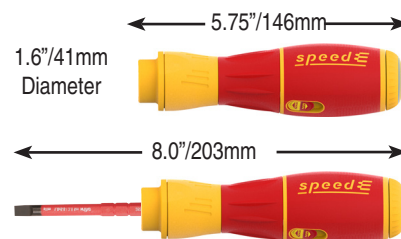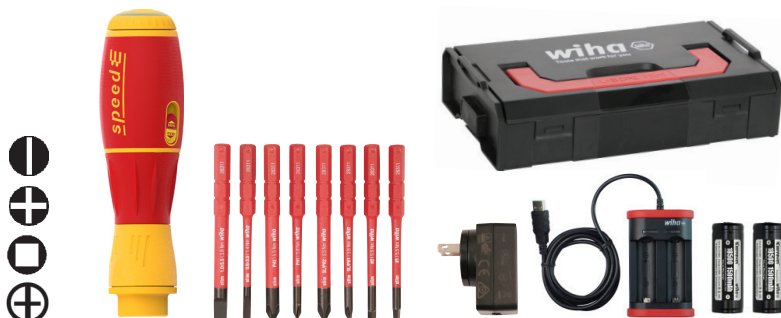

Packaging
H 2-5/8"
W 10-1/4"
L 6-1/8"

32490 13 Pc. speedE®II Electric Screwdriver With SlimLine Blades

Certified to EN ISO, BS EN, ASME. Set includes speedE®II electric 0.4 & 1.0 Nm handle, 8 Insulated SlimLine blades, 2 Li-Ion rechargeable batteries & wall plug adapter/charger.

Item No.	speedE®II Handle Range: 0.4 Nm & 1.0 Nm
32490	Insulated SlimLine Blades Include:
	SlimLine Slotted: #3.5, 5.5mm
	SlimLine Phillips: #1, #2
	SlimLine Square: #1, #2
	SlimLine Terminal Xeno SI/Ph: #1, #2

*speedE electric screwdriver is only insulated when used with Wiha SlimLine blades



speedE®II made in Germany
Set contains global components

1 Year Warranty

Within 30 days of purchase register your speedE®II at:
USA / MEXICO / SOUTH AMERICA www.wihatools.com/register
CANADA www.wihatools.ca/register

Flyer #99032

wiha 
Tools that work for you

Wiha Tools, Ltd.
1348 Dundas Circle
Monticello, MN 55362

Tel 800.494.6104
Fax 763.295.6598
Cservice@wihatools.com
www.wihatools.com