

# PRO-SIGNAL



## Volume Control 100v 50w - White PSG03180

**Please read these instructions carefully before use and retain for future reference.**

### **IMPORTANT SAFETY INFORMATION**


*When using electrical appliances basic safety precautions should always be followed.*

- To prevent fire or shock hazard, do not expose this product to rain or moisture.
- To avoid electrical shock, turn off and disconnect the 100V speaker input at the source device before opening this product.

### **OVERVIEW**

10 step speaker volume control which is ideal for low/ moderate sound installations. The unit is suitable for flush mounting or surface mounting using the back box supplied.

## INSTALLATION

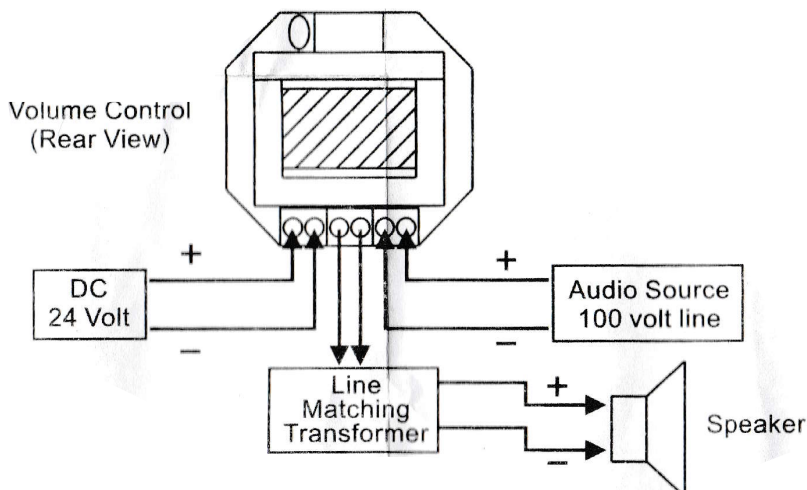

## SPECIFICATIONS

- 10 step attenuation (0 is Off).
- Screw type termination for speedy installation.
- 24V Relay.
- 35Hz - 20kHz Frequency response.
- Can be flushed mounted into a 45mm deep 1G UK back box.
- White plastic front panel and control.

## CLEANING & MAINTENANCE

- Clean the outside panel with a soft cloth lightly moistened with a mild detergent.
- Never use any abrasive or solvents.



INFORMATION ON WASTE DISPOSAL FOR CONSUMERS OF ELECTRICAL & ELECTRONIC EQUIPMENT.

When this product has reached the end of its life it must be treated as Waste Electrical & Electronic Equipment (WEEE). Any WEEE marked products must not be mixed with general household waste, but kept separate for the treatment, recovery and recycling of the materials used. Contact your local authority for details of recycling schemes in your area.



Made in Taiwan  
PR2 9PP  
Man Rev 1.0