




2101S-140

ERGO™ Side Cutting Pliers with Insulated Handles and Phosphate Finish 140 mm



PRODUCT DETAILS

- Two-component ERGO™ insulated handles: thermoplastic surface on tough polypropylene provides superior grip
- Suitable for cutting Cu, Fe+ and piano wire
- Insulated side cutting pliers developed according to the scientific ERGO™ process for working on live equipment up to 1000 V
- Comfortable 1000 V insulated handles
- Distance from joint to centre of cutting edges is reduced for greater leverage and increased cutting capacity
- High-performance alloy steel
- Phosphate finish, anti-corrosion treated
- Cutting radius progresses along edge in order to cut hard material such as piano wire close to the joint as well as soft materials
- Screw joint provides excellent running and accurate alignment of cutting edges
- Round-shaped jaws give improved accessibility in confined spaces
- Induction hardened cutting edges
- Heavy-duty induction hardened cutting edge
- Less effort required compared to conventional cutting pliers
- Reduced shank width ideally for carrying in the pocket
- Each and every tool is tested to 10.000V for 10 seconds at the end of the manufacturing cycle

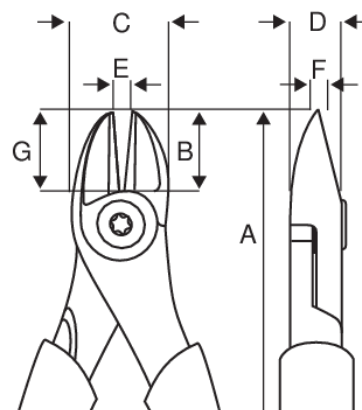


 


Follow the Fish!



PRODUCT ATTRIBUTES

Product: **2101S-140**

A	140 mm	B	16,4 mm	C	19 mm
D	8 mm	E	1.5 mm	F	1.3 mm
G	16,4 mm	 Cu	3.7 mm	 Fe+	2.0 mm
 Plano	1.8 mm	 g	126 g		

