
 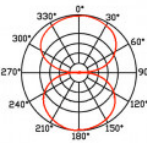


RM8

RIBBON STUDIO MICROPHONE



Description

The RM8 ribbon microphone is made following the strictest construction standards which make it the ideal microphone for any professional application.

Equipped with Double-sided 0,02 mm pure aluminum foil for an excellent vocal range and acoustic instruments image, even in the most difficult mixing circumstances.

The package includes a shockmount support, windscreen filter and a sturdy aluminum carrying case.

Double-sided 0,02 mm pure aluminium foil
Wide low-frequency range and fast transient response
WIMA capacitors
Integrated shockmount support

Technical Specifications RM8

Type Ribbon Microphone
Polar pattern Figure-8
Frequency response 20 Hz - 20 KHz
Sensitivity - 34 dB +/- 2 dB (0 dB = 1VPa @ 1 KHz)
Max SPL for 1% THD 130 dB
S/N Ratio 79 dB
Impedance 200 Ω +/- 30% (at 1kHz)
Recommended Load Impedance 1000 Ω
Power Requirement 48 V Phantom Power
Connector 3 Pin XLR Male
Weight 474 g
Dimensions 50 O x 190 mm
Accessories Shockmount