

NEBO

HIGH BRIGHT 6000

LIGHT MODE

- 6,000 lumens: 80 meters

DESIGN


- Three 90° adjustable LED panels
- Quick and easy installation
- 600% more light than standard 60W bulb
- Energy efficient - only 60W

OPERATION

- Standard screw base; switch ON to activate

SPECS

- 0.75 lbs.
- Collapsed size: (H)4.97" x (W) 5.1" x (D) 4.55"

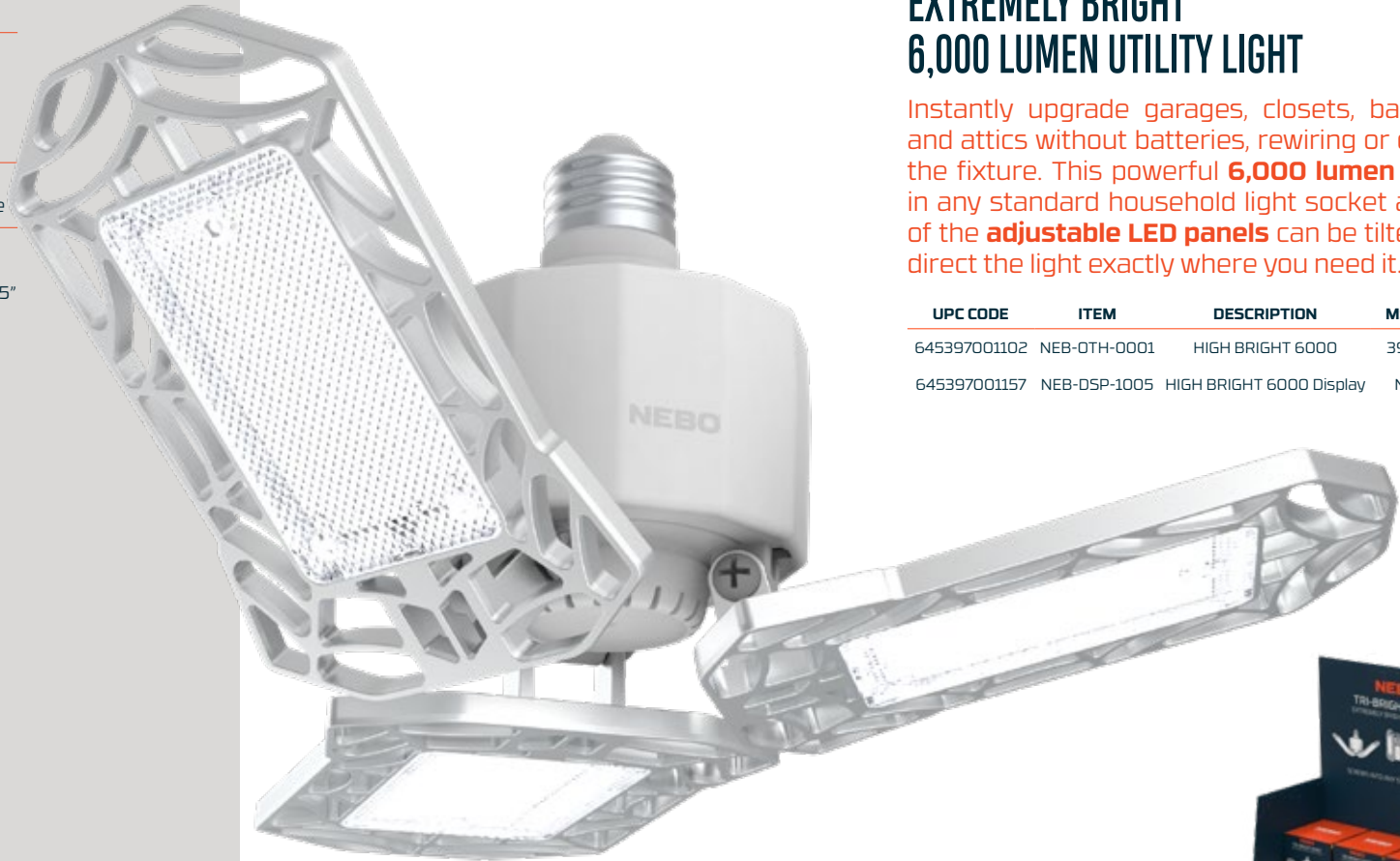

EXTREMELY BRIGHT 6,000 LUMEN UTILITY LIGHT

Instantly upgrade garages, closets, basements and attics without batteries, rewiring or changing the fixture. This powerful **6,000 lumen light** fits in any standard household light socket and each of the **adjustable LED panels** can be tilted 90° to direct the light exactly where you need it.

UPC CODE	ITEM	DESCRIPTION	MSRP
645397001102	NEB-OTH-0001	HIGH BRIGHT 6000	39.99
645397001157	NEB-DSP-1005	HIGH BRIGHT 6000 Display	N/A

Display sold separately

Display Dimensions

(H) 50" x (W) 19" x (D) 12.5"

Gift Box Dimensions

(H) 6" x (W) 5.9" x (D) 5.86"

