

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** **0150220430**  
**Status:** **Active**  
**Overview:** FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers  
**Description:** 0.50mm Pitch Premo-Flex LVDS Jumper, 102.00mm Cable Length, Gold (Au) Plating, 30 Circuits

**Documents:**

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Cable
Series	<u>15022</u>
Crimp Quality Equipment	Yes
Overview	<u>FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers</u>
Product Name	Premo-Flex LVDS Jumper
UPC	889056697354

**Physical**

Cable Length	102.00mm
Circuits (Loaded)	30
Contact Layout Type	A (same side)
Material - Outer Jacket	Polyester
Material - Plating Mating	Gold
Net Weight	0.100/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +80°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Cable


**Electrical**

Current - Maximum per Contact	0.5A
Voltage - Maximum	30V AC

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing	SD-15022-030
---------------	--------------

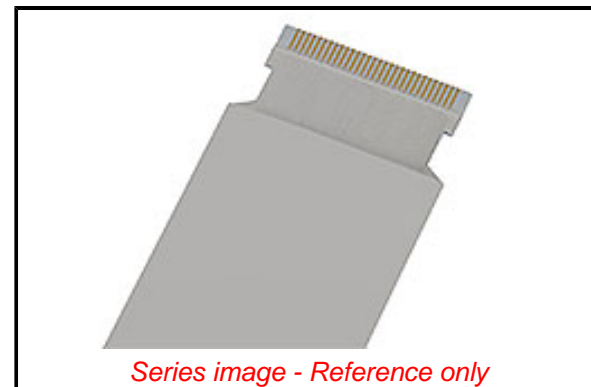

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
-ED/88/2018 (15  
January 2019)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

15022 Series

**Mates With**

Easy-On FFC/FPC Connector [5017863091](#) ,  
[5017863092](#) , [5018643091](#) , [5018643092](#)