

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0150222450](#)
Status: **Active**
Overview: FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Description: 0.50mm Pitch Premo-Flex LVDS Jumper, 610.00mm Cable Length, Gold (Au) Plating, 50 Circuits

Documents:

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable
Series	15022
Crimp Quality Equipment	Yes
Overview	FFC Cable Jumpers, Premo-Flex Flat-Flexible Cable Jumpers
Product Name	Premo-Flex LVDS Jumper
UPC	889056697514

Physical

Cable Length	610.00mm
Circuits (Loaded)	50
Contact Layout Type	A (same side)
Material - Outer Jacket	Polyester
Material - Plating Mating	Gold
Net Weight	12.800/g
Packaging Type	Bag
Pitch - Mating Interface	0.50mm
Temperature Range - Operating	-40° to +80°C
Wire Size AWG	N/A
Wire/Cable Type	Flat Cable


Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	30V AC

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-15022-050
---------------	--------------

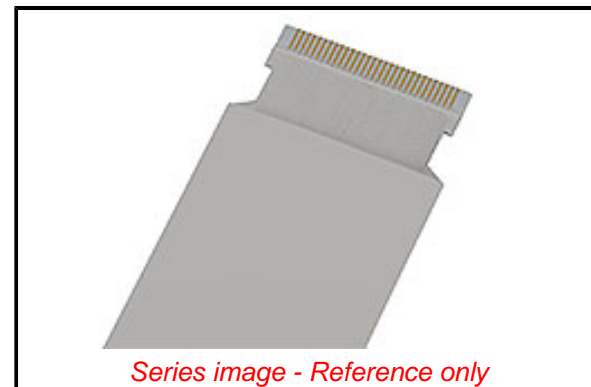

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[15022 Series](#)

Mates With

Easy-On FFC/FPC Connector [5017865090](#) ,
[5017865091](#) , [5018645090](#) , [5018645091](#)