


The powerful high-pressure washer with in-hand powercontrol for allround use

This powerfull Nilfisk high pressure washer with in hand power control for adjustable water pressure while cleaning easily handles your cleaning tasks.

The ultra torque engine and long life metal pump provides the power to clean everything from soft and sensitive surfaces to blasting away ingrained dirt up to 40 m2/hour. With the ultraflex hose cleaning tasks are no hassle and the integrated hose reel makes stow away easy.

- 140 max pressure
- Long life metal pump
- Cleaning speed index: 40
- Automatic start/stop system
- Gentle & Rough nozzles system with user guidance
- Trolley for high mobility
- Click&Clean connectivity for quick and easy change of accesories
- Internal Hose reel
- 8m Ultraflex hose
- Nozzle user guide
- In Hand Power Control

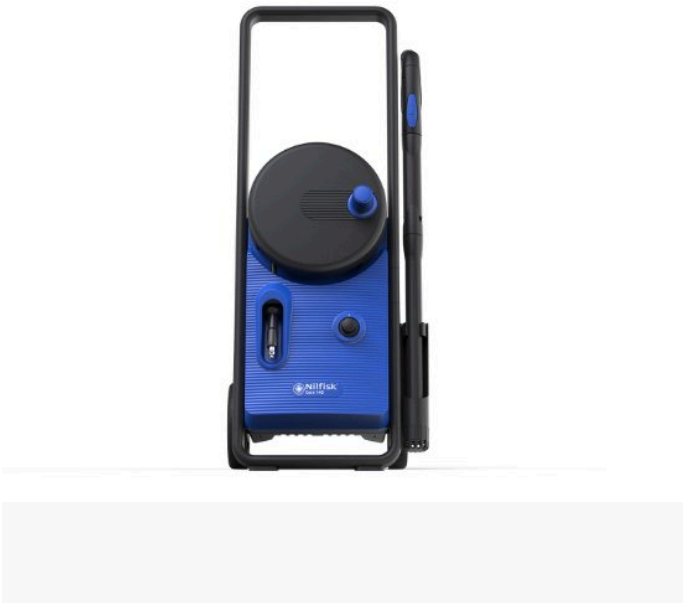








Picture shown may not represent model quoted

● Standard equipment

Included accessories		Ref. no.	Min. required	CORE 140-8 IN HAND POWERCONTROL UK
Nozzle - High Pressure Washer				
	C&C GENTLE NOZZLE (TORNADO)	128500076	0	●
	C&C ROUGH NOZZLE (POWERSPEED)	128501153	0	●
	Under Chassis Nozzle	6411135	0	
	Wide Angled Auto & Cycle Nozzle	6411136	0	
Brush				
	Auto Brush	6411131	0	
	FIXED BRUSH SHORT NILFISK SP	128500685	0	



The powerful high-pressure washer with in-hand powercontrol for allround use

Included accessories		Ref. no.	Min. required	CORE 140-8 IN HAND POWERCONTROL UK
Accessory				
	C&C FOAMSPRAYER WITH BOTTLE	128500077	0	•
	CLEANING TOOL BLACK	6520844	0	•
	Compact Patio	128500700	0	
	DRAIN AND TUBE 8M	128500461	0	
	G3 LANCE	126481134	0	•
	NILFISK ACCESSORY HOLDER CORE 140	128501319	0	
	NILFISK C&C SUPER FOAM SPRAYER	128500938	0	
	Patio Cleaner	128500702	0	

Model	CORE 140-8 IN HAND POWERCONTROL UK
Ref. no.	128471255

PRODUCT FEATURES

Trolley	•
Hose reel	•
Aluminium pump	•
Lance and spray gun storage	•
Storage of accessories	•
Cable storage	•
Click&Clean (C&C) nozzle concept	•



The powerful high-pressure washer with in-hand powercontrol for allround use




Model	CORE 140-8 IN HAND POWERCONTROL UK
Ref. no.	128471255

PRODUCT FEATURES

Gun with quick connection and swivel	•
Automatic start/stop	•
Soft grip	
Hose and cable holder	•
Telescopic handle	
Wireless PowerGrip	•
Pressure regulation in nozzle	












Technical specifications	CORE 140-8 IN HAND POWERCONTROL UK
Pump pressure (bar/MPa)	Max 140 / max 14
Rated power (kW)	1,8
Voltage/phase/frequency/current (V~/Hz/A)	230 - 240 / 1~/ 50-60 / 7
Water flow Qmax/Qiec (l/h)	474 / 348
Cable length (m)	5
Hose length (m)	8
Max. inlet temperature (°C)	40
Length x width x height (cm)	88,2 x 37,1 x 30
Weight (kg)	9,2

● Standard equipment, ○ Supplementary accessories, □ Mountable equipment

Accessories		Ref. no.	Min. required	CORE 140-8 IN HAND POWERCON- TROL UK
Brush				
	Auto Brush	6411131	0	○
	CAR BRUSH HEAD	128500463	0	○
	FIXED BRUSH SHORT NILFISK SP	128500685	0	○














The powerful high-pressure washer with in-hand powercontrol for allround use

Accessories		Ref. no.	Min. required	CORE 140-8 IN HAND POWERCON- TROL UK
	GARDEN BRUSH HEAD	128470457	0	○
	RIM BRUSH HEAD	128470458	0	○
	Rotary Brush	126411395	0	○
	ROTARY BRUSH	6410762	0	○
Accessory				
	C&C FOAMSPRAYER WITH BOTTLE	128500077	0	●
	CLEANING TOOL BLACK	6520844	0	●
	Compact Patio	128500700	0	○
	DRAIN AND TUBE 8M	128500461	0	○
	DRAIN AND TUBE CLEANER 15M	6410766	0	○
	G3 LANCE	126481134	0	●
	INLET SUCTION HOSE 3M	128500673	0	○













The powerful high-pressure washer with in-hand powercontrol for allround use

Accessories		Ref. no.	Min. required	CORE 140-8 IN HAND POWERCON- TROL UK
	MULTI ANGLE ADAPTER	6411138	0	○
	MULTI BRUSH	128470456	0	○
	NILFISK ACCESSORY HOLDER CORE 140	128501319	0	○
	NILFISK C&C SUPER FOAM SPRAYER	128500938	0	○
	NILFISK POWER PATIO	128500955	0	○
	NILFISK TOWEL	128501316	0	○
	NILFISK WASHING GLOVE	128501317	0	○
	NILFISK WATER FILTER	128500674	0	○
	Patio Cleaner	128500702	0	○
	ROOF CLEANER	128470040	0	○
	Under Chassis Spray Lance	6410763	0	○
	VSB SET - GREEN	6410891	0	○



The powerful high-pressure washer with in-hand powercontrol for allround use

Accessories		Ref. no.	Min. required	CORE 140-8 IN HAND POWERCONTROL UK
	Water Emptying Kit	126411387	0	○
Nozzle - High Pressure Washer				
	C&C GENTLE NOZZLE (TORNADO)	128500076	0	●
	C&C ROUGH NOZZLE (POWERSPEED)	128501153	0	●
	Under Chassis Nozzle	6411135	0	○
	Wide Angled Auto & Cycle Nozzle	6411136	0	○
Hose and Connection				
	EXT. HOSE 7 M - QUICK COUPLING	106411346	0	○
	NILFISK BA VALVE COMP. GARDENA	106411177	0	○
Accessory Kit				
	MULTI BRUSH KIT	128470459	0	○
	NILFISK CAR WASH KIT TOWEL WASHING MIT	128501318	0	○
	O-RING KIT CONSUMER HPW	128500292	0	○