


BL23E22-01

Rated Voltage: 24Volts, Rated Current: 3.2 Amps

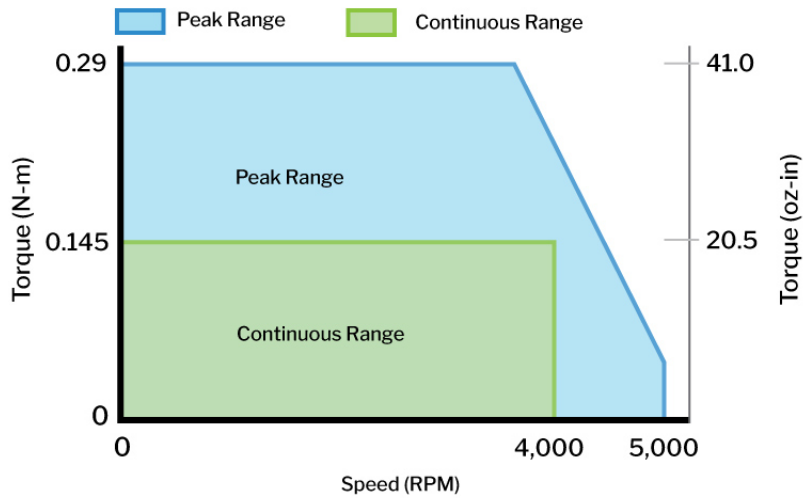

0

& &0

& 0


- &00&
- &0 -

- &0 0T-
0


00

0


OPERATION & USAGE TIPS

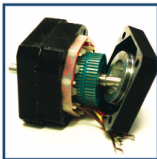


Do not disassemble motors; a significant reduction in motor performance will occur.

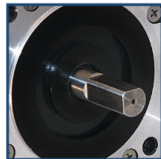


Do not machine shafts; this will have a negative effect on shaft run out and perpendicularity.

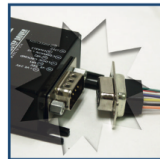

Do not disconnect motor from drive while in operation.

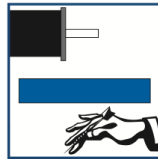

Do not use holding torque/detent torque of motor as a fail safe brake.

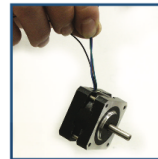

Do not hold motor by lead wires.



Do not exceed the rated current; this will burn the motor.

FAILURE TO COMPLY WITH THESE RECOMMENDATIONS WILL VOID ALL WARRANTY TERMS

Motion Control, Solved.
MOTOR ENGINEERING & MANUFACTURING



Optimized For Your Application



Quick Prototype Turnaround



Small Batch to OEM Volume Production



US Based Support & Manufacturing