


Input Cable for 12 Die High Power Mixing LED

ILR-XM01-CABLE24-200MM

Product Overview

200mm input cable for TSLC 12-Die family products from ILS

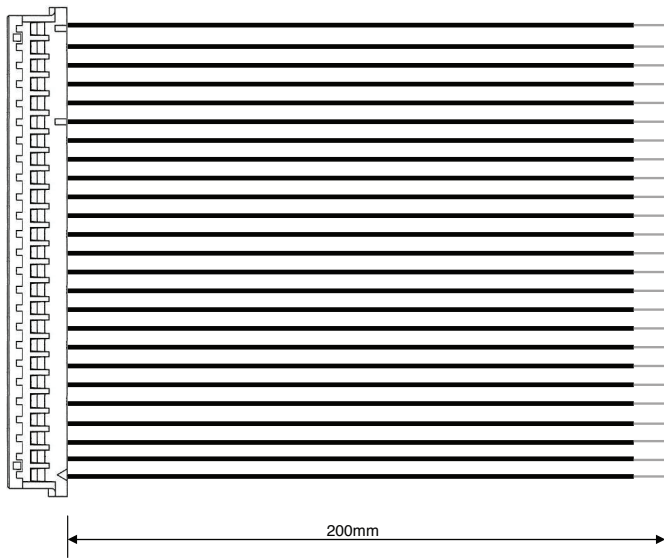

Technical


- 28awg UL1061 Black Wires
- 25 x CTL 205mm
- Strip 1 x 1.5, 1 x 3
- Strip and Tin all free ends 3mm

Target crimp height

- DF14 Tag 0.55mm
- Pull off 13.35n or better

ILR-XM01-CABLE24-200MM is compatible with the following products:

Part Number	Description
ILR-XM01-001A-SC201-CON25.	12 Die LED array version 001A - Full Spectrum
IHR-XM01-002A-SC201-CON25.	12 Die LED array version 002A - Horticultural
ILR-XM01-003A-SC201-CON25.	12 Die LED array version 003A - Tuneable White
ILR-XM01-004A-SC201-CON25.	12 Die LED array version 004A - White & IR
ILR-XM01-005A-SC201-CON25.	12 Die LED array version 005A - RGBW

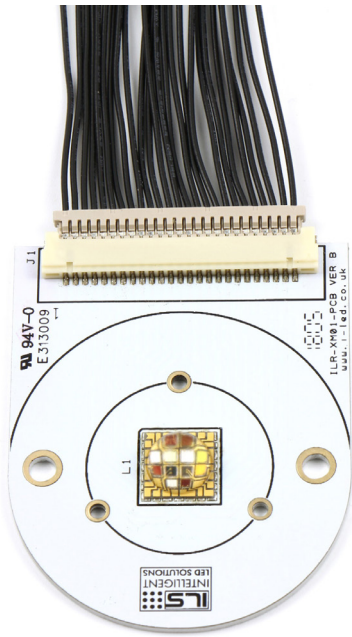

For further information please contact ILS.

The values contained in this data sheet can change due to technical innovations. Any such changes will be made without separate notification.