

# Expression Premium XP-7100

## DATASHEET / BROCHURE



Advanced all-in-one printer with an ADF that produces outstanding glossy photos and documents, and comes with a range of easy-to-use features.

This stylish, top-of-the-range, compact all-in-one is ideal for busy households who want to print outstanding glossy photos and crisp, clear documents. Wi-Fi connectivity and mobile printing offer great flexibility, while features such as A4 double-sided printing, an Automatic Document Feeder (ADF) and a 10.9cm touchscreen help make this device quick and easy to use.

### Stylish and versatile

Unsightly tech is a thing of the past; this all-in-one looks great from every angle. It features an Automatic Document Feeder for scanning and copying single or double-sided multi-page documents, dual paper trays for A4 and photo media, double-sided A4 printing to save paper and a rear speciality paper feed for printing on thicker media.

### Best of both worlds

Enjoy the beauty of high-quality photos and crisp, clear text documents with the five-colour Claria Premium dye and pigment ink set. Photos are crystal clear with vibrant colours and deep, rich blacks as Claria Premium incorporates a photo black ink cartridge.

### Mobile printing


Print using smart devices with Epson's free apps, Wi-Fi, and Wi-Fi Direct. Print and scan wirelessly with Epson's iPrint<sup>1</sup> app or try Epson's Creative Print<sup>1</sup> app to print photos from Facebook, create greeting cards and more. And print from almost anywhere in the world by emailing files to the printer with Epson Email Print<sup>1</sup>.

### Fuss-free features

There's a 10.9cm interactive touchscreen and a memory card slot for easy navigation and printing photos directly without a computer. It's also possible to print on suitable CDs and DVDs. For even easier operation, a motorised control panel and output tray mean hassle-free printing.

## KEY FEATURES

- **Compact wireless all-in-one**  
Print, scan, copy
- **Mobile printing**  
Freedom to print and scan from almost anywhere<sup>1</sup>
- **Automatic Document Feeder**  
Scan and copy multiple documents
- **Flexible paper trays**  
Two front-loading trays and a rear feed
- **10.9cm interactive touchscreen**  
Easy navigation and PC-free photo printing from a memory card

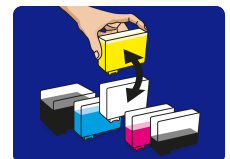

## PRODUCT SPECIFICATIONS

### TECHNOLOGY

Printing Method	Epson Micro Piezo™ print head
Nozzle Configuration	360 Nozzles Black, 180 Nozzles per Color
Minimum Droplet Size	1.5 pl, With Variable-Sized Droplet Technology
Ink Technology	Claria™ Premium Ink
Printing Resolution	5,760 x 1,440 DPI
All-in-One Functions	Print, Scan, Copy

### PRINT

Printing Speed ISO/IEC 24734	15.8 pages/min Monochrome, 11 pages/min Colour
Maximum Printing Speed	12 Seconds per 10 x 15 cm photo (Epson Premium Glossy Photo Paper), 32 pages/min Colour (plain paper 75 g/m²), 32 pages/min Monochrome (plain paper 75 g/m²)
Colours	Black, Photo Black, Cyan, Yellow, Magenta

For detailed information on printing speeds please visit <http://www.epson.eu/testing>.

### SCAN

Optical Resolution	1,200 DPI x 4,800 DPI (Horizontal x Vertical)
Scanner type	Contact image sensor (CIS)

### PAPER / MEDIA HANDLING

Number of paper trays	2
Paper Formats	Legal, 16:9, 13 x 18 cm, 10 x 15 cm, Letter, No. 10 (Envelope), DL (Envelope), C6 (Envelope), B5 (17.6x25.7 cm), A6 (10.5x14.8 cm), A5 (14.8x21.0 cm), A4 (21.0x29.7 cm), User defined
Duplex	Yes (A4, plain paper)
Print Margin	0 mm top, 0 mm right, 0 mm bottom, 0 mm left (Wherever margin is defined. Otherwise 3mm top, left, right, bottom.)
Automatic Document Feed	30 pages
Paper Tray Capacity	100 Sheets Standard, 20 Photo Sheets
Rear paper path (special media)	Yes
Media Handling	Auto Sheet Feeder, Automatic duplex (A4, plain paper), Borderless print, CD/DVD print, Rear specialty media feed

### GENERAL

Supply Voltage	AC 220 V - 240 V, 50 Hz - 60 Hz
Product dimensions	390 x 339 x 183 mm (Width x Depth x Height)
Compatible Operating Systems	Mac OS X 10.6.8 or later, Windows 10, Windows 7, Windows 8, Windows 8.1, Windows Vista, Windows XP SP3, XP Professional x64 Edition SP2
Included Software	Epson Easy Photo Print, Epson Print CD, Epson Scan
Interfaces	USB, Ethernet, WiFi, Wi-Fi Direct, USB host, SD Card Slot
Mobile and Cloud printing services	Apple AirPrint, Google Cloud Print, Epson Connect (iPrint, Email Print, Remote Print Driver, Scan-to-Cloud, Facebook print)
Energy Use	8.7 Watt (Ready), 0.4 Watt (Power off), 16 Watt (standalone copying, ISO/IEC 24712 pattern), 1.2 Watt (sleep mode)

### OTHER FEATURES

Panel	Type: Color, Touchscreen, Diagonal: 10.9 cm
Memory Cards	SDXC, SDHC, SD, MiniSDHC*, MiniSD*, MicroSDXC*, MicroSDHC*, MicroSD* (* Adaptor required, not supplied in box)
Features	Touchscreen, PictBridge, Red eye removal, Photo Enhance, Direct print from USB

### OTHER

Warranty	12 months Carry in Optional warranty extension available
----------	---

## Expression Premium XP-7100

### WHAT'S IN THE BOX

- Software (CD)
- Setup guide
- Power cable
- Main unit
- Individual Ink Cartridges
- Warranty document

## LOGISTICS INFORMATION

SKU	C11CH03401
EAN code	8715946651859
Country of Origin	Indonesia
Layer	2 Units
Layer Block	4 Units

## Expression Premium XP-7100

### INK YIELD DATA



Oranges 33

Oranges 33XL



250 pages\*

530 pages\*



200 photos\*

400 photos\*



300 pages\*

650 pages\*

\* Approx. page yield based on ISO/IEC 24711/24712 or ISO/IEC 29102/29103. Actual yield will vary depending on images printed and usage conditions. For more information visit <http://www.epson.eu/pageyield>

### INK CARTRIDGE COMPATIBILITY



### RECOMMENDED PAPER



Photo Paper  
Glossy



Value Glossy  
Photo Paper



For more information please contact:

Home users: 0343 90 37766  
Business users\*: 0871 42 37766  
Republic of Ireland: 01 436 7742  
Or visit us at <https://www.epson.co.uk/contactus>  
\* 10p per minute plus network extras.

Web: [www.epson.co.uk](http://www.epson.co.uk)  
[www.epson.ie](http://www.epson.ie)

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners.  
Product information is subject to change without prior notice.  
Last extracted: 2020-07-07

1. Epson iPrint and Epson Creative Print require a wireless connection and the Epson printing apps. Epson Email print, Epson Remote Print Driver and Epson scan-to cloud require an internet connection. For more information, supported languages and devices, please visit [www.epsonconnect.eu](http://www.epsonconnect.eu)

**EPSON®**