

Product Data Sheet for KleenGuard® G10 Blue Nitrile Gloves - 24cm Ambidextrous / Blue

Product Information

Customer Facing Code	57370 - 57374
Description	KleenGuard® G10 Blue Nitrile Gloves - 24cm Ambidextrous / Blue
PDS Reference	25/11/2020
Status	On Sale

Packaging Configuration

Case Contents	57370: 10 Dispenser Boxes x 100 Gloves = 1000 Gloves 57371: 10 Dispenser Boxes x 100 Gloves = 1000 Gloves 57372: 10 Dispenser Boxes x 100 Gloves = 1000 Gloves 57373: 10 Dispenser Boxes x 100 Gloves = 1000 Gloves 57374: 10 Dispenser Boxes x 90 Gloves = 900 Gloves
Outer Pack Material	Corrugated

Packaging and Palletisation

Code/Size	ITF Barcode	EAN Barcode	Case LWH (cm)	Net/Gross Weight (kg)	Pallet Type	Pallet LWH (m)	Cases per Pallet	Inner Gross Weight (Kg)
57370-XS	30680651573705	036000573701	41 x 27 x 26	5.89/6.6	E5	1.20 x 0.80 x 1.44	8 x 5 =40	0.60
57371-S	30680651573712	036000573718	41 x 27 x 26	6.52/7.33	E5	1.20 x 0.80 x 1.45	8 x 5 =40	0.70
57372-M	30680651573729	036000573725	41 x 27 x 26	6.46/7.27	E5	1.20 x 0.80 x 1.44	8 x 5 =40	0.70
57373-L	30680651573736	036000573732	41 x 27 x 26	6.89/7.7	E5	1.20 x 0.80 x 1.45	8 x 5 =40	0.70
57374-XL	30680651573743	036000573749	41 x 27 x 26	8.019/8.83	E5	1.20 x 0.80 x 1.44	8 x 5 =40	0.90

Product Description

KleenGuard® G10 gloves are designed to provide maximum comfort and protection for tasks where safety and flexibility is key. The gloves' synthetic nitrile rubber material provides extra resistance and durability when compared with latex, making them the ideal choice for hand protection. These gloves are powder and latex free to reduce allergies and contamination. Available as ambidextrous gloves, 0.12 thickness, with beaded cuff for added strength and textured fingertips for improved grip. With a wide size range of XS to XL and an ambidextrous design, KleenGuard® gloves are perfectly suited for any user and come in a portable dispenser box for mobility and easy access. This product is certified for food contact and is up to the standard of BfR XXI, which is considered the benchmark for food legislation in Europe. This makes it perfect for use in any environment where food preparation is involved. Also popular for use in automotive, warehousing, transport, cleaning, food processing and catering applications. Glove size 0.12mm (Thick) x 24cm (L). For other glove sizes, see product codes 57371, 57372, 57373 and 57374. 10 boxes x 90 ambidextrous, blue gloves, XL, (900 total)

Product Data Sheet for KleenGuard® G10 Blue Nitrile Gloves - 24cm Ambidextrous / Blue

Features and Benefits

Features	Benefits
Ambidextrous	Reduces time – improves efficiency Excellent “cost in use”
Beaded cuff	For easy donning
CE Marked – Category 1	Sign of quality and protection
Independently accredited	Suitable for Food Handling
Latex Free	Reduces potential for Type 1 glove – associated reactions, Eliminates the potential risk of Type I reactions
Powder free	To avoid skin allergies, Minimises drying effect of powder on skin
Textured fingertips	To help grip, Excellent tactile sensitivity

Product Configuration

Sterile	No	Latex Free	Yes
Main Protection Type	General purpose	Application	Industrial
Ambidextrous	Yes	Powdered	No
Material	Nitrile	Coated	No
Liner	No	Coating	No
Colour	Blue	AQL	1.5
Chlorinated	Yes	Cuff Style	Rolled Beaded
Length	240 mm		

International Standards and Symbols

Solution


Safer Workplace

We know staff safety is your top priority. You can rely on our solutions to protect them, their environment and your important work.



Productive Workplace


The success of your business hinges on your work efficiency. That's why our solutions are designed to help improve your productivity.

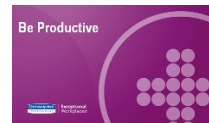

Standard R+E

Food Contact Regulations

This product is suitable for food contact and complies with Regulation (EC) No. 1935/2004. Furthermore, nitrile rubber gloves comply with Regulation (EC) No. 10/2011 and German Recommendation, BfR No. XXI, and paper products comply with German Recommendation, BfR No. XXXVI.

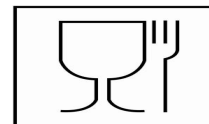

CE Mark

Simple - CAT I, Intermediate - CAT II or Complex - CAT III



Trade

ISO 9001

This gives the requirements for quality management systems, is now firmly established as the globally implemented standard for providing assurance about the ability to satisfy quality requirements and to enhance customer satisfaction in supplier-customer relationships.



Product Data Sheet for KleenGuard® G10 Blue Nitrile Gloves - 24cm Ambidextrous / Blue

Packaging

Unit Of Sale	Case	Max Weight(kg)	9.71
Case Dimension(LXWXH)(cm)	41 x 27 x 26	Inner Pack Material	Cartonboard

Instructions

The open book pictogram - indicates that the user should read and understand the USER INSTRUCTIONS before using the garment.

Protect from heat and radioactive sources.

Keep Dry. Store in a cool, dry place.

Single use only.

Information

It is the employer's responsibility to assess the risk of the task to be undertaken and determine the correct choice of personal protective equipment for the task. The manufacturer, Kimberly-Clark, does not accept any responsibility for the incorrect choice or misuse of the personal protective equipment shown in this brochure. All care has been taken to ensure that the information contained herein is as accurate as possible at the time of publication, however errors may occur and legislation concerning personal protective equipment is under constant review and may change in the lifetime of this brochure. Accordingly, the specification for the products may be subject to change. We would advise you to contact INFOFAX if you have any queries concerning the products shown or the suitability of such products for a particular task. Always dispose of used protective equipment in a safe and appropriate manner in accordance with European, National and Local environmental regulations.

Websites	www.kcprofessional.co.uk	Storage conditions	Keep dry. Store in a cool dry place and shield from exposure to direct sunlight, intense artificial light or exposure to sources of radiation or ozone.
Durability	This product has a five years shelf life from the date of manufacture.		
Customer Service Number	For more information please contact Customer Service during regular office hours-0870 551 044		
Country of Origin	MALAYSIA		