



Model No.: **GP476AF**

Description	: Mercury Free & Lead Free Alkaline High Voltage Battery
Nominal Voltage	: 6Volts
Nominal Dimensions	: Ø13.0mm×25.2mm
Terminal	: Nickel plated flat contacts - protruded red(+); recessed black (-)
Jacket	: Metal jacket
Internal Connection	: Pressure
Applications	: Electronic toy, photo
Average Weight	: 10g
Date Code	: Unless otherwise specified, each batteries will carry a numeric year code and analogue month code
Shelf Life	: Not less than 90% of the service capacity within first year storage at 20 ± 2 °C 55 ± 20 %RH
Insulation	: 5MΩ min.
Resistance	
Close Circuit Voltage	: 5.2 Volts (min.)(load resistor 1KΩ at 20 ± 2 °C for 0.1 to 2 seconds)
Nominal Service Life	: 125hrs (at 6kΩ load) (to 3.6V at 20 ± 2 °C)
Average Service Capacity	: 105mAh(at 6kΩ load) (to 3.6V at 20 ± 2 °C)

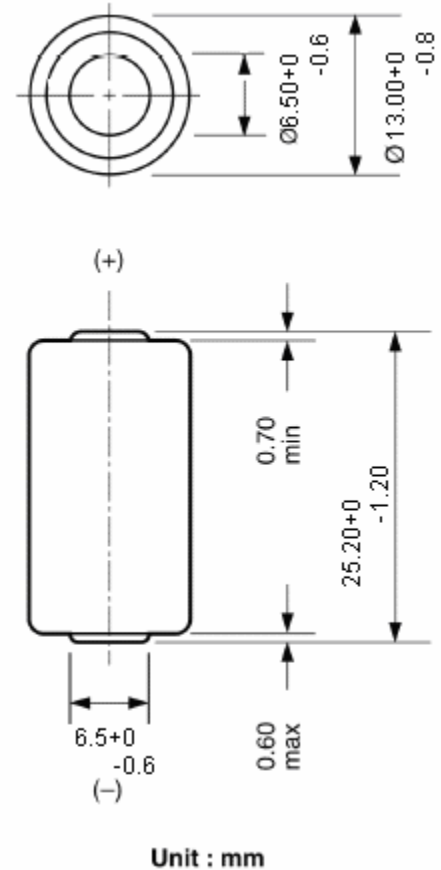

Typical Discharge characteristics at 20 ± 2°C

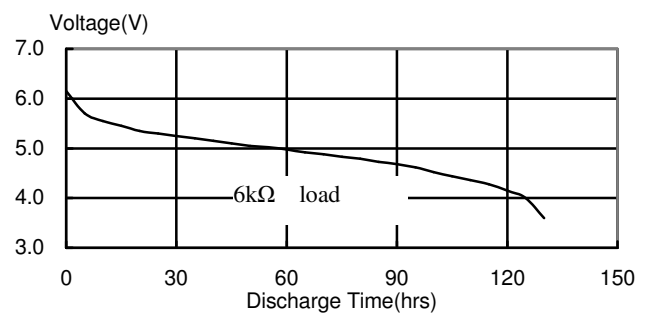

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.