


WorkForce ES-50

DATASHEET / BROCHURE

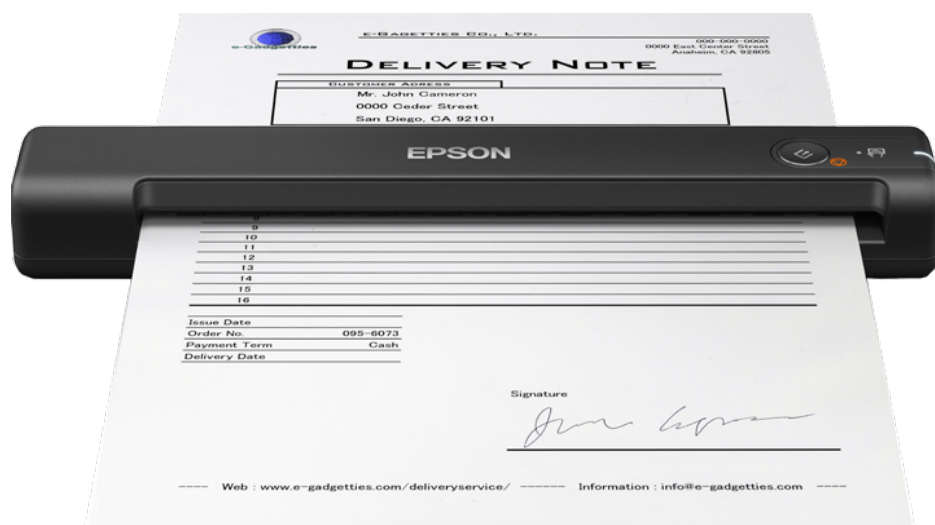

This latest mobile A4 scanner makes it easy to scan in compact SOHO environments, or even take on the road when needed.

The ES-50 can quickly be transported and set up, making it easy to stay highly organised anywhere there is access to a USB socket, including a laptop or PC. It's ideal for SOHO environments with limited space where a simple scanning solution is required.

Scan anywhere

The compact design and USB connectivity make it easy to use the ES-50 wherever it's needed.

Highly organised

Epson's new ScanSmart software makes it effortless for anyone to scan how they want, providing an easy-to-use step by step scanning solution. Users can save and send files in common formats like PDF, jpeg, tiff and many more. Continuous scanning with automatic feed mode speeds up the scanning process, while the CIS sensor delivers instant scanning with no warm up time.

Flexible

The ability to scan a wide range of document and media types makes this model a reliable asset. It handles paper from 35gsm to 270gsm, and long paper up to 1.8 metres.

KEY FEATURES

- **Scan anywhere**
Small, lightweight design
- **USB connectivity**
Powered by USB
- **Fast scanning speeds**
At up to 5.5 seconds per page
- **Simplify your workload**
Continuous scanning with automatic feed mode
- **Includes new ScanSmart software**
Get scanning quickly and easily

PRODUCT SPECIFICATIONS

TECHNOLOGY

Scanner Type	Mobile Scanner
Optical Resolution (ADF)	600 DPI x 600 DPI (Horizontal x Vertical)
Optical Resolution	600 DPI x 600 DPI (Horizontal x Vertical)
Paper Formats	Legal, Business cards, A4 (21.0x29.7 cm), A5 (14.8x21.0 cm), A6 (10.5x14.8 cm), A3 with stitching function, A7 (7.4x10.5 cm), A8 (5.2 x 7.4 cm), B5 (17.6x25.7 cm), B6 (12.5x17.6 cm), Postcard, Letter, Plastic cards
Scanning color depth	Input: 48 Bits Color / 16 Bits Monochrome , Output: 24 Bits Color / 8 Bits Monochrome
Category	Small & Compact, General Office

SCANNER

Optical Sensor	CIS (Contact Image Sensor)
Light Source	ReadyScan LED technology
Output Resolution	600 DPI

SCAN SPEED

Scanning Speed	Monochrome: 5.5 s/page - Color: 5.5 s/page measured with Size: A4 , Resolution: 200 / 300 dpi
----------------	---

PAPER / MEDIA HANDLING

Paper Setting Capacity	1 Sheets
Paper weight	Auto loading: 35 - 270 g/m², Manual loading:35 - 270 g/m²
Reliability Daily Duty Cycle	300 pages
Duplex Scan	No

SCANNING FEATURES

Features	One keypress, RGB colour dropout, Skip blank page, Punch holes removal, Advanced editing, Pre-defined scanning settings, Automatic area segmentation, Automatic de-skew, Automatic B/W colour original detection, RGB colour enhance, Dual Image Output (Windows only), Auto-rotation, Text enhancement, Edge fill, Advanced cropping feature for Auto size, Descreening
Output formats	JPEG, PDF, searchable PDF, PDF/A
File compression features	JPEG compression
Scanning Volume	300 Pages per day

CONNECTIVITY

Interfaces	Hi-Speed USB - compatible with USB 2.0 specification
------------	--

GENERAL

Product dimensions	272 x 47 x 34 mm (Width x Depth x Height)
Product weight	0.27 kg
Drivers	WIA, SANE (Linux), ICA (Mac)
Included Software	Epson Scan 2, Epson ScanSmart
Compatible Operating Systems	Mac OS 10.6+, Windows 10, Windows 7, Windows 8, Windows 8.1, Windows Server 2003, Windows Server 2008 (32/64bit), Windows Server 2012 R2, Windows Server 2016, Windows Vista, Windows XP
Supported Humidity	Operation 10% - 85%, Storage 10% - 90%
Supported Temperature	Operation 5° C - 35° C, Storage -25° C - 60° C

OTHER

Warranty	24 months Carry in Optional warranty extension available
----------	---

WorkForce ES-50

WHAT'S IN THE BOX

- USB cable
- User guide
- Cleaning Sheets

OPTIONAL ACCESSORIES

- Maintenance Sheet (set of 2)
B12B819481
- Carrier Sheet
B12B819451

WorkForce ES-50

LOGISTICS INFORMATION

SKU	B11B252401
EAN code	8715946656908
Dimensions Single Carton	360 x 350 x 320 mm
Carton Weight	0 Kg
Country of Origin	China
Layer	60 Units
Layer Block	60 Units

For more information please contact:

Home users: 0343 90 37766
Business users*: 0871 42 37766
Republic of Ireland: 01 436 7742
Or visit us at <https://www.epson.co.uk/contactus>
* 10p per minute plus network extras.

Web: www.epson.co.uk
www.epson.ie

Trademarks and registered trademarks are the property of Seiko Epson Corporation or their respective owners.
Product information is subject to change without prior notice.
Last extracted: 2020-12-03

EPSON[®]