


Senk-Bits 90°

Countersink Bit 90°

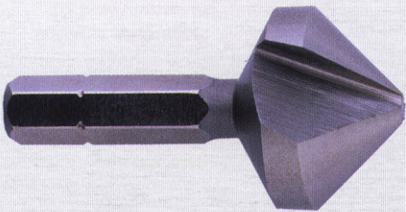

Art. 825

HSS, Senk-Kopf nach
DIN 335 Form C, mit 1/4"
Bitschaft Antrieb (DIN 3126) und
3 Schneiden.

HSS, Countersink head in
conformity with DIN 335,
Form C, with 1/4 Inch drill shank
(DIN 3216) and 3 Flutes.

CODE	mm	M	mm	g	EURO	EAN-CODE
05641	6,3	M 3	31	7	6,94	056418
05642	8,3	M 4	31	8	6,94	056425
05643	10,4	M 5	34	10	7,91	056432
05644	12,4	M 6	35	12	8,88	056449
05645	16,5	M 8	40	18	9,90	056456
05646	20,5	M 10	41	21	11,24	056463

Senk-Bits 90° in Stahlblechkassette

Countersink Bit 90° in steel-plate cassette



Art. 825-650

HSS, Senk-Kopf nach
DIN 335 Form C, mit 1/4"
Bitschaft Antrieb (DIN 3126) und
3 Schneiden.

HSS, Countersink head in
conformity with DIN 335,
Form C, with 1/4 Inch drill shank
(DIN 3216) and 3 Flutes.

384-185

CODE	No.	Inhalt	g	EURO	EAN-CODE
05649	825-650	6,3 8,3 10,4 12,4 16,5 20,5 Handgriff mit 1/4" Innensechskant-Aufnahme Universalhalter Nr. 825-25 Bohrpaste	600	77,64	056494