



# 4A Smart Battery Charger and Maintainer



**Safe and easy-to-use.**  
**For traditional and Stop/Start batteries.**

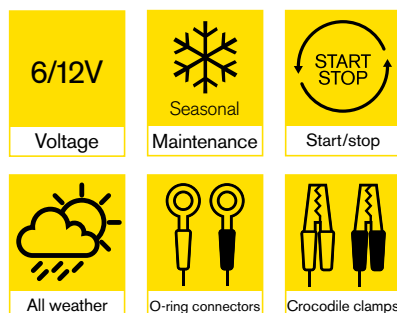

 - **6V and 12V compatible**
- **Up to 2A or 4A charge rate selection**
- **Stop/Start compatible**
- **7-Stage charging process**
- **Large LCD display screen**  
Clearly shows voltage and charging progress
- **Cold weather charging mode**  
Protects batteries in cold temperatures
- **Quick connectors**  
With clamps or O-ring terminals for long term connection
- **One button operation for ease-of-use**
- **Backlit display can be seen in low light**
- **Reverse polarity protection**
- **Short-circuit protection**
- **Connect and be sure**  
Automatically adjusts to long-term maintenance mode when battery is full



## Specifications

Product Code	RSC804 (UK), RESC804 (EU)
Voltage Output	6/12V DC
Voltage Input	220-240V AC
Charger rate	Up to 4A
Battery Type	Lead Acid, Gel, Calcium, EFB & AGM
Max. Battery Capacity	90Ah battery charging 140Ah maintenance mode
Min. Battery Capacity	4Ah
Product Dimensions	H225 x W115 x D113mm
Case Quantity	6 x 1
Barcode	5055175245140 (UK), 5055175245201 (EU)