

# ORIGINAL LINE H1

Original spare part



## The cost-effective original spare parts

OSRAM ORIGINAL LINE halogen lamps offer convincing performance for standard requirements, are robust and cost-effective. They have already been successfully used in millions of new cars from renowned manufacturers, whether as standard initial equipment or original spare parts. Convince yourself of the excellent value for money, the reliable OEM quality and the wide product range of the ORIGINAL LINE.

Technical data

Product information

Order reference	64150
Application (Category and Product specific)	Halogen headlight lamp

Electrical data


Power input	68 W <sup>1)</sup>
Nominal voltage	12.0 V
Nominal wattage	55.00 W
Test voltage	13.2 V

<sup>1)</sup> Maximum

Photometrical data

Luminous flux	1550 lm
Luminous flux tolerance	±15 %
Color temperature	3200 K

Dimensions & weight

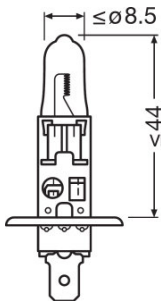

Diameter	9 mm
Product weight	6.89 g
Length	67.5 mm

Lifespan

Lifespan B3	400 h
Lifespan Tc	650 h

Additional product data

Base (standard designation)	P14.5s
-----------------------------	--------

## Product datasheet

### Capabilities

Technology	HAL
------------	-----

### Certificates & standards

ECE category	H1
--------------	----

### Country specific categorizations

Order reference	64150
-----------------	-------

### Country specific information

Product code	METEL code	SEG-No.	STK number	UK Org
4050300001487	OSRA64150	-	-	-
4050300206820	OSRA64150	-	-	-
4050300001487	OSRA64150	-	-	-
4050300925264	OSRA64150BLI1	-	4730314	-
4050300925264	OSRA64150BLI1	-	4730314	-

### Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4050300001487	ORIGINAL LINE H1	Folding carton box 1	25 mm x 23 mm x 70 mm	0.04 dm <sup>3</sup>	8.00 g
4050300206820	ORIGINAL LINE H1	Bundle 10	79 mm x 68 mm x 90 mm	0.48 dm <sup>3</sup>	82.00 g
4050300206837	ORIGINAL LINE H1	Shipping carton box 100	361 mm x 109 mm x 122 mm	4.80 dm <sup>3</sup>	915.00 g
4050300925264	ORIGINAL LINE H1	Blister 1	- x - x -		24.00 g
4008321142009	ORIGINAL LINE H1	Shipping carton box 10	225 mm x 145 mm x 107 mm	3.49 dm <sup>3</sup>	242.33 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

### Download Data

File
------

	360 Degree Image ORIGINAL H1 64150
---	---------------------------------------

Application advice

For more detailed application information and graphics please see product datasheet.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.



OSRAM