

NIGHT BREAKER LASER H1

Halogen light with excellent brightness



Up to 150% more brightness

More light allows to see farther and therefore react sooner compared to the minimum legal standard



Up to 150 m long beam

For better visibility



Up to 20% whiter light

More modern look compared to the minimum legal standard



Strong halogen light for high demands

Thanks to innovative laser ablation technology, NIGHT BREAKER LASER halogen headlight lamps shine up to 150% brighter compared to the minimum legal standard. The highly engineered filament ensures an extra light boost. Consequently, the lamps provide an up to 150m long beam and up to 20% whiter light compared to the minimum legal standard. More light and improved visibility can help drivers identify and react to traffic hazards more quickly. Last but not least: OSRAM NIGHT BREAKER LASER impresses with its unique design (laser-engraved product name) and complete portfolio (H1, H3, H4, H7, H8, H11, HB3, HB4).

Technical data

Product information

Order reference	64150NL
Application (Category and Product specific)	Halogen headlight lamp

Electrical data


Power input	68 W ¹⁾
Nominal voltage	12.0 V
Nominal wattage	55.00 W
Test voltage	13.2 V

¹⁾ Maximum

Photometrical data

Luminous flux	1550 lm
Luminous flux tolerance	±15 %
Color temperature	3200 K

Dimensions & weight

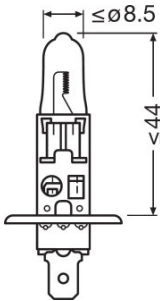

Diameter	9 mm
Product weight	6.00 g
Length	67.0 mm

Lifespan

Lifespan B3	150 h
Lifespan Tc	300 h

Additional product data

Base (standard designation)	P14.5s
-----------------------------	--------

Product datasheet

Capabilities

Technology	HAL
------------	-----

Certificates & standards

ECE category	H1
--------------	----

Country specific categorizations


Order reference	64150NL
-----------------	---------

Logistical Data

Product code	Product description	Packaging unit (Pieces/Unit)	Dimensions (length x width x height)	Volume	Gross weight
4052899991309	NIGHT BREAKER LASER H1	Folding carton box 1	25 mm x 23 mm x 70 mm	0.04 dm ³	8.00 g
4052899991316	NIGHT BREAKER LASER H1	Bundle 10	- x - x -		
4052899991323	NIGHT BREAKER LASER H1	Shipping carton box 100	122 mm x 109 mm x 361 mm	4.80 dm ³	905.00 g
4062172114899	NIGHT BREAKER LASER H1	Hard Cover Box 2	114 mm x 48 mm x 106 mm	0.58 dm ³	104.00 g
4062172114905	NIGHT BREAKER LASER H1	Shipping carton box 10	268 mm x 126 mm x 125 mm	4.22 dm ³	605.00 g
4062172114936	NIGHT BREAKER LASER H1	Blister 1	135 mm x 95 mm x 24 mm	0.31 dm ³	28.00 g
4062172114943	NIGHT BREAKER LASER H1	Shipping carton box 10	225 mm x 105 mm x 145 mm	3.43 dm ³	237.00 g

The mentioned product code describes the smallest quantity unit which can be ordered. One shipping unit can contain one or more single products. When placing an order, for the quantity please enter single or multiples of a shipping unit.

Download Data

File
 360 Degree Image NIGHT BREAKER LASER next gen H1 64150NL

Legal advice

Light output compared to the minimum ECE R112/R37 requirements

H4/H7/H8/H11/HB3/HB4

Product datasheet

Application advice

For more detailed application information and graphics please see product datasheet.

Disclaimer

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.



OSRAM