

HiLook

Great View, Great Value

Product Code:

TCK-T1250-PIRL



5MP Super HD + PIR

2 Analogue Turret CCTV Cameras

For HiLook Analogue CCTV Kit



**ACCURATE
ALERT**

Using built-in PIR (passive infrared) sensor technology, only warm heat sources will be detected, meaning you will avoid false alerts from scenarios such as moving trees.



**ACTIVE
DEFENCE**


With the brightly lit LED emitting upon detection, you can ensure an additional level of security from your system, designed to deter suspicious activity.



**EXIR
ENHANCED
NIGHT VISION**

EXIR (Extended Infrared) enhances night vision by reducing the centred brightness and spreading the exposure to darker areas, giving a more complete and bright image.

hikvision.com/uk/products/HiLook

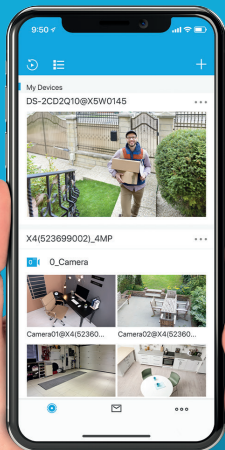

HILOOKVISION



Enjoy Live Views across multiple cameras and manage your devices using the HiLookVision App or PC Client, powered by the HiLookvision Cloud Server.



Real-Time Monitoring



Video Playback



Motion Detection Alarm Notification



5MP SUPER HD RESOLUTION

Exceptional high-resolution video for seeing every detail up close or from far away.



PIR-ENHANCED MOTION DETECTION

The kit utilises each camera's built-in PIR detector to reduce false alarms, guaranteeing improved accuracy - furthermore, the camera will deploy a flashing strobe to deter intruders.



WEATHERPROOF & DUSTPROOF IP67

Withstand wind, rain and snow in temperatures ranging from -40°C to 60°C (-40°F to 140°F).

THC-T150-PMPIRL DAY/NIGHT 5MP PIR CAMERA

Video

Video Quality	5MP (2560 x 1944 pixels)
Viewing Angle	2.8 mm, horizontal FOV: 85.5°, vertical FOV: 63.8°, diagonal FOV: 110.7°

Night Vision

Night Vision Distance	EXIR, up to 65ft / 20 m IR distance
-----------------------	-------------------------------------

General

PIR Sensor Range	110°, 36ft / 11 m
PIR Detection	ACCURATE ALERT & ACTIVE DEFENCE
Indoor / Outdoor	Indoor or Outdoor, IP67 rated
Audio Microphone	No
Operating Temperature	-40 °C to 60 °C (-40 °F to 140 °F)
Dimensions	Ø 109.8mm x 89.75mm (Ø 4.32" x 3.53")