

HiLook

Great View, Great Value

Product Code:
TCK-B1250-PIRL



5MP Super HD + PIR 2 Analogue Bullet CCTV Cameras

For HiLook Analogue CCTV Kit



ACCURATE
ALERT

Using built-in PIR (passive infrared) sensor technology, only warm heat sources will be detected, meaning you will avoid false alerts from scenarios such as moving trees.



ACTIVE
DEFENCE

With the brightly lit LED emitting upon detection, you can ensure an additional level of security from your system, designed to deter suspicious activity.




EXIR

ENHANCED
NIGHT VISION

EXIR (Extended Infrared) enhances night vision by reducing the centred brightness and spreading the exposure to darker areas, giving a more complete and bright image.

hikvision.com/uk/products/HiLook

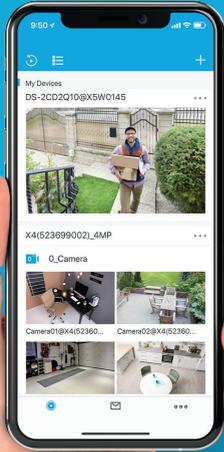

HILOOKVISION



Enjoy Live Views across multiple cameras and manage your devices using the HiLookVision App or PC Client, powered by the HiLookvision Cloud Server.



Real-Time Monitoring



Video Playback



Motion Detection Alarm Notification



5MP SUPER HD RESOLUTION

Exceptional high-resolution video for seeing every detail up close or from far away.



PIR-ENHANCED MOTION DETECTION

The kit utilises each camera's built-in PIR detector to reduce false alarms, guaranteeing improved accuracy - furthermore, the camera will deploy a flashing strobe to deter intruders.



WEATHERPROOF & DUSTPROOF IP67

Withstand wind, rain and snow in temperatures ranging from -40°C to 60°C (-40°F to 140°F).

THC-B150-PMPIRL DAY/NIGHT 5MP PIR CAMERA

Video

Video Quality 5MP (2560 x 1944 pixels)
Viewing Angle 2.8 mm, horizontal FOV: 85.5°, vertical FOV: 63.8°, diagonal FOV: 110.7°

Night Vision

Night Vision Distance EXIR, up to 65ft / 20 m IR distance

General

PIR Sensor Range 110°, 36ft / 11 m
PIR Detection ACCURATE ALERT & ACTIVE DEFENCE
Indoor / Outdoor Indoor or Outdoor, IP67 rated
Audio Microphone No
Operating Temperature -40 °C to 60 °C (-40 °F to 140 °F)
Dimensions (W x D x H) 68mm x 70mm x 179.8mm (2.68" x 2.76" x 7.08")