

#24186

## On-Ear USB Headset

Compact on-ear USB headset with soft ear cushions and adjustable headband

### Key features

- Compact size for a subtle look during video calls
- Comfortable design with soft leatherette ear cushions
- Adjustable headband, allows anyone to wear this headset with ease
- Clear digital speech and audio quality through USB
- Adjustable microphone that can be placed in multiple positions
- The 1.8m long cable assures plenty of freedom of movement during calls



### What's in the box

- Headset
- User guide

### System requirements

- Windows 10, 8, or 7
- macOS 10.15 (Catalina) or higher
- USB port



1.8 METER  
CABLE



COMFORTABLE  
EAR CUSHIONS



USB  
CONNECTION



VOLUME  
CONTROL



### The Easy Way to Communicate

It's an online world, which means meetings are moving to the internet as well. The Trust HS-200 is there to help. This compact headset is made to be worn comfortably, with an adjustable microphone to help you communicate. Easy to use, with great sound quality; suitable for all (video) chat applications, like Skype, Teams or Zoom. And thanks to the easy-to-open and sustainable packaging, you don't have to worry about wasting resources; the packaging is fully recyclable and the headset itself works the moment you plug it into your PC or laptop.

### Compact Comfort

The Trust HS-200 has a convenient, compact design. The subtle look of these headphones make them perfectly suitable for use on camera without distraction. Thanks to the soft leatherette ear cushions, adjustable headband and light weight, the Trust HS-200 will stay comfortable even during the longest of video calls.




### Clear Digital Speech

Place the adjustable microphone in any position you like and make yourself heard. The USB connection will ensure your colleagues or distant family members will be able to hear your every word in clear, digital quality. It also makes the Trust HS-200 easy to use, as simply plugging in the USB cable is all you need to do to get started.

### Suitable for All

While the Trust HS-200 can be used comfortably by anyone, it's also suitable for all (video) chat apps. Whether you prefer Teams, Skype or Zoom, the Rydo supports it without issues. The 180cm long USB cable allows plenty of freedom of movement, which is especially handy if you like to move around a lot during meetings, while the inline remote gives you full control over your mic and volume. The Trust HS-200 truly is suitable for all.

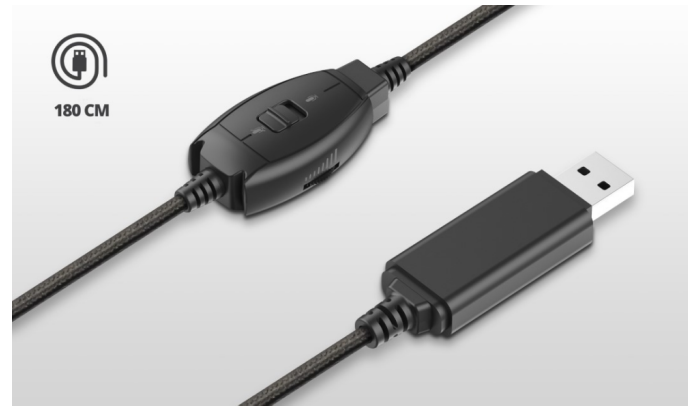

## GENERAL

Height of main product (in mm)	140 mm	Width of main product (in mm)	180 mm
Depth of main product (in mm)	60 mm	Total weight	146 g
Weight of main unit	146 g		

## CONNECTIVITY

Connection type	Wired	Bluetooth	False
USB version	2.0	Connector type	USB-A male
Connector style	Straight	Cable style	Nylon braided
Cable detachable	False	Cable length main cable	180 cm

## LIGHTING

Lights	False
--------	-------

## MICROPHONE

Sensor type microphone	Condenser	Pick-up pattern	Omnidirectional
Frequency response microphone	150 - 14000 Hz	Noise reduction	False

## AUDIO

Sound reproduction	Stereo	Audio channels	2.0
Frequency response	20 - 20000 Hz	Driver size	24 mm
Driver units	2	Microphone	True
Detachable microphone	False	True Wireless Stereo (TWS)	False

## HEADPHONE

Adjustable headband	True	Earcup type	On-ear
Ear-cup material	Synthetic leather	Ear-cap construction	Closed-back
Swivel earcups	False	Rotating earcups	False
Output channels	2	Magnet type	Neodymium
Sensitivity	105 dB	Active Noise Cancelling	False
Total harmonic distortion	5 %	Ear-cap contact pressure	Normal
Foldable	False		

## INPUT

Power source	USB
--------------	-----

**CONTROL**

<b>Remote control</b>	Inline	<b>Controls on earcap</b>	False
<b>Controls</b>	Mute, volume	<b>LED indicators</b>	False

**FEATURES**

<b>Background noise reduction</b>	False	<b>Software</b>	False
-----------------------------------	-------	-----------------	-------

**COMPATIBILITY**

<b>Suitable for</b>	Business use, Home, Office	<b>Compatible Device Types</b>	Laptop, pc
<b>Compatible Software Platforms</b>	Mac OS, Windows		



PRODUCT VISUAL 1



PRODUCT ESHOT 1



PRODUCT VISUAL 2



PRODUCT SIDE 1



PRODUCT SIDE 2



PRODUCT FRONT 1




PRODUCT EXTRA 1




PRODUCT EXTRA 2



PACKAGE VISUAL 1

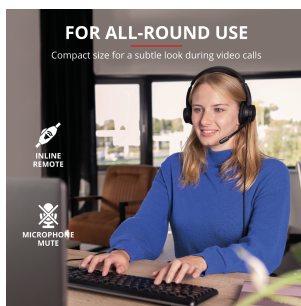

PRODUCT PICTORIAL 1

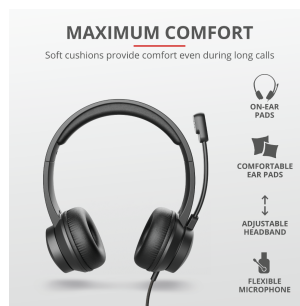

PRODUCT PICTORIAL 2



PRODUCT PICTORIAL 3