




1731090680

FCT Standard-Density D-Sub Connector, Female, Right-Angle, PCB Through Hole, Gold Plating, 200 Mating Cycles, 15 Circuits

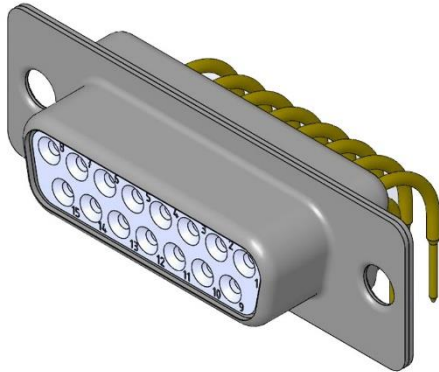

#### Mates With Part(s):

FCT Standard-Density D-Sub, Size 2, 15 Position, Plug

#### General

Status	Active
Category	D-Sub Products
Series	<a href="#">173109</a>
IP Rating	IP20
Overview	<a href="#">FCT D-Sub Connectors</a>
Product Category	D-Sub Connector



Product Name	FCT Products
Type	Standard Density
UPC	191128954105
Circuits (Loaded)	15
Circuits (maximum)	15
Color - Resin	White
Durability (mating cycles max)	200
Gender	Female
Material - Contact	Copper Alloy
Material - Resin	PBT
Material - Shell	Steel
Net Weight	9.300/g
Number of Rows	2
Orientation	Right-Angle
PC Tail Length	11.10mm
PCB Locator	Yes



PCB Retention	Yes
PCB Thickness - Recommended	1.60mm
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Flange
Pitch - Mating Interface	2.84mm
Pitch - Termination Interface	2.54mm
Plating - Contact	Gold over Nickel
Plating - Shell	Tin
Polarized to Mating Part	Yes
Polarized to PCB	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-55° to +125°C
Termination Style	Through Hole
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20