



Energizer® Vision Ultra HD Rechargeable Headlamp HDFRLP

The *Energizer®* Vision Ultra HD Rechargeable Headlamp brings outstanding performance in a compact design. The headlamp shows innovative features with its rechargeability (USB port) and the *Energizer®* Smart Dimming technology which allows for easy control of light intensity. In addition to the white LEDs, this light has green and red LEDs which preserve night vision for outdoors activities such as hunting and fishing. The VisionGuard technology gradually increases the light intensity to prevent a high beam straight in the users' eyes. Includes USB charging cable.




Provides
400
Lumens of
Light



Provides
Run Time
of 4 Hours



Sustains 1
Meter
Drop Test

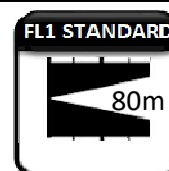

Illuminates
objects
80m away



Water Resistant
IPX4 – works after
splashing water
on all sides

DESIGN BENEFITS

- ✓ Rechargeable
- ✓ *Energizer®* Smart Dimming technology to control light intensity
- ✓ VisionGuard protects vision by gradually increasing light intensity
- ✓ Red and Green LEDs for night vision
- ✓ Water-resistant with shatterproof lens
- ✓ Pivoting head

LIGHT AND POWER SOURCE

- ✓ Features LED Technology
- ✓ Rechargeable: Lithium ion non-removable battery

ELECTRICAL CHARACTERISTICS

Electrical Characteristics Nominal Power:
Power consumption 3.6W / Battery 103040 Li-ion 3.7V dc
LED Specifications: LED 3.0V cc / 1200mA

CERTIFICATES AND COMPLIANCE

CE RoHS
EMC, EN62471, FCC



This device complies with part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) This device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation.

Tested according to ANSI/NEMA FL1 Standards.

*Light must be turned off while charging.

PERFORMANCE BENEFITS

- ✓ Rechargeable - Fully charge in 4 hours*
- ✓ Up to 15X Brighter than Standard LED Technology
- ✓ Long Run Time in High and Low modes
- ✓ 7 modes: High, Low, Wide, Wide Low, Red, Flashing Red, Green

SPECIFICATIONS

Weight Including Battery:

80 Grams / 2.8 Ounces

Dimensions:

60mm x 46mm x 39mm / 2.36" x 1.81" x 1.54"

NUMBER OF OPERATING MODES: 7

Mode	Lumens	Runtime (h)	Beam Distance (m)
High	400	4	80
Wide	200	5	30
Wide Low (dim)	--	--	--
Low	20	15	25
Red	--	--	--
Flashing Red	--	--	--
Green	--	--	--

Before using your flashlight, please read all instructions and cautionary marking on the package and the light.

This datasheet contains information specific to products manufactured at the time publication. Contents do not constitute a claim or warranty.

©2018 Energizer