

Energizer® Keychain Light with *Touch Tech* Technology

TKC2C

The *Energizer*® Keychain Light with *Touch Tech* Technology combines patented technology for easy, intuitive use. With the switchless innovation of Touch Tech, users get instant illumination just by grasping the light. Just release your grip when done using, and Touch Tech smoothly turns off the light. Touch Tech ensures that your light is never left on accidentally and helps extend battery life. This technology makes this keychain light very convenient and easy to use.




Provides
20
Lumens of
Light



Provides
Run Time
of 5 Hours



Sustains 1
Meter
Drop Test.

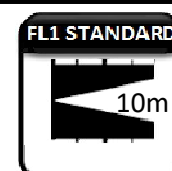

Illuminates
objects up
to 10m
away.

DESIGN BENEFITS

- ✓ Switchless on/off touch power
- ✓ Designed for maximum convenience
- grip the light for instant illumination
and release it to smoothly turn off
- ✓ Compact size make it a convenient
light to have at all times

LIGHT AND POWER SOURCE

- ✓ Features LED Technology
- ✓ Operates on 2 x CR2032 *Energizer*®
Coin Cells (Included)

ELECTRICAL CHARACTERISTICS

Electrical Characteristics Nominal Power:
Power consumption 0.3W / Batteries
Energizer CR2032 6.0V dc
LED Specifications: LED 3.0V cc / 100 mA

CERTIFICATES AND COMPLIANCE

CE RoHS
EMC, EN62471,



Tested according to ANSI/NEMA FL1 Standards.

Results based on: Energizer CR2032

PERFORMANCE BENEFITS

- ✓ Up to 10X brighter than standard LED
Technology
- ✓ Long Run Time

SPECIFICATIONS

Weight Excluding Batteries:

34 Grams / 1.19 Ounces

Dimensions:

60mm x 25mm x 13mm / 2.34" x 0.98" x
0.51"

NUMBER OF OPERATING MODES: 1

Mode	Lumens (lm)	Runtime (h)	Beam Distance (m)
On	20	5	10

Before using your flashlight, please read all instructions and cautionary marking on the package and the light.

This datasheet contains information specific to products manufactured at the time publication. Contents do not constitute a claim or warranty.

©2018 Energizer