




Provides
50
Lumens of
Light



Provides
Run Time
of 5 Hours
and 30
minutes

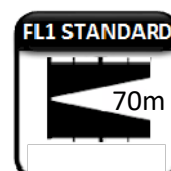

Illuminates
objects up
to 70m
away.

DESIGN BENEFITS

LIGHT AND POWER SOURCE

- ✓ Incandescent bulb
- ✓ Operates on 1 3R12 Battery

ELECTRICAL CHARACTERISTICS

Electrical Characteristics Nominal Power:
Power consumption xxW / Batteries AAA
Energizer 3R12 xxV dc
LED Specifications: LED 3.0V cc / xxx mA

CERTIFICATES AND COMPLIANCE



EMC, EN62471, FCC



Tested according to ANSI/NEMA FL1 Standards.

PERFORMANCE BENEFITS

SPECIFICATIONS

NUMBER OF OPERATING MODES: 1

Mode	Lumens (lm)	Runtime (h)	Beam Distance (m)
On	14	5.5	70