



MASTER LEDtube InstantFit HF T5

Master LEDtube HF 1500mm HO 26W 840 T5 OE

Philips MASTER LEDtube InstantFit T5 integrates a LED light source into a traditional fluorescent form factor. Its unique design creates a perfectly uniform visual appearance which cannot be distinguished from traditional fluorescents. The Philips MASTER LEDtube InstantFit T5 is the ideal solution for customers who have higher light output requirements and want to maximise value over the lifetime. The full energy savings & longer lifetime result in attractive payback times and TCO benefits.


Product data

General Information		Operating and Electrical	
Cap base	G5 [G5]	Input frequency	20 K to 140 K Hz
EU RoHS compliant	Yes	Power (Rated) (Nom)	26 W
Nominal lifetime (nom.)	60000 h	Lamp current (max.)	420 mA
Switching cycle	50,000X	Lamp current (min.)	150 mA
Technical type	26-49W	Starting time (nom.)	0.5 s
Light Technical		Warm-up time to 60% light (nom.)	0.5 s
Colour Code	840 [CCT of 4,000 K]	Power factor (nom.)	0.9
Beam Angle (Nom)	200 °	Voltage (Nom)	60-120 V
Luminous flux (nom.)	3900 lm	Temperature	
Colour designation	Cool White (CW)	T-ambient (max.)	45 °C
Correlated Colour Temperature (Nom)	4000 K	T-ambient (min.)	-20 °C
Luminous efficacy (rated) (nom.)	150.00 lm/W	T storage (max.)	65 °C
Colour consistency	<6	T storage (min.)	-40 °C
Colour rendering index (nom.)	80	T-Case maximum (nom.)	50 °C
LLMF at end of nominal lifetime (nom.)	70 %		

MASTER LEDtube InstantFit HF T5


Controls and Dimming	
Dimmable	Yes – Check ballast compatibility
Mechanical and Housing	
Lamp Finish	Frosted
Bulb material	Glass
Product length	1500 mm
Bulb shape	Tube, double-ended
Approval and Application	
Energy efficiency label (EEL)	A++
Energy-saving product	Yes
Approval marks	RoHS compliance CE marking KEMA Keur certificate

Dimensional drawing

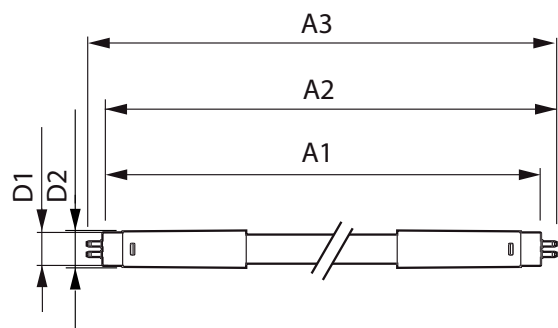

TLED 1500mm HF 26W 3900lm 4000K G5


Photometric data

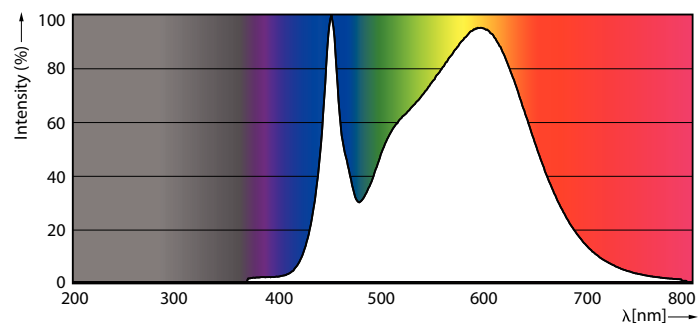

LEDtube MAS 26W G5 3900lm 840

Energy consumption kWh/1,000 hours	26 kWh
Product Data	
Full product code	871869974959000
Order product name	Master LEDtube HF 1500mm HO 26W 840 T5
	OE
EAN/UPC – product	8718699749590
Order code	74959000
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
SAP material	929002352402
SAP net weight (piece)	0.380 kg


Product	D1	D2	A1	A2	A3
Master LEDtube HF 1500mm	15.5 mm	19 mm	1449 mm	1456 mm	1463 mm
HO 26W 840 T5 OE					

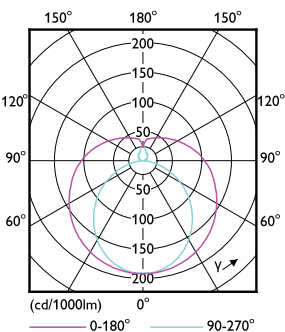

LEDtube MAS 26W G5 3700lm

MASTER LEDtube InstantFit HF T5


Photometric data

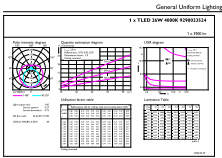


General Uniform Lightness
Page 1 of 10

LEDtube MAS 26W G5 3900lm 840 1500mm


Lifetime

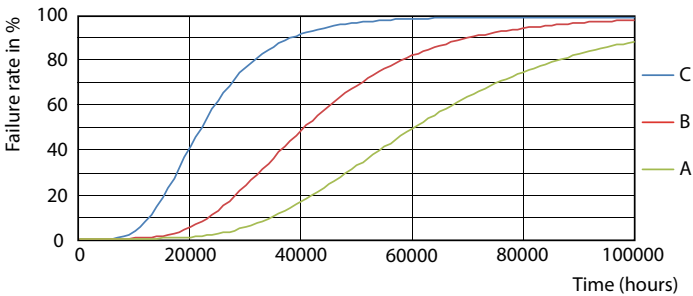


LEDtube_60K_FailureRate

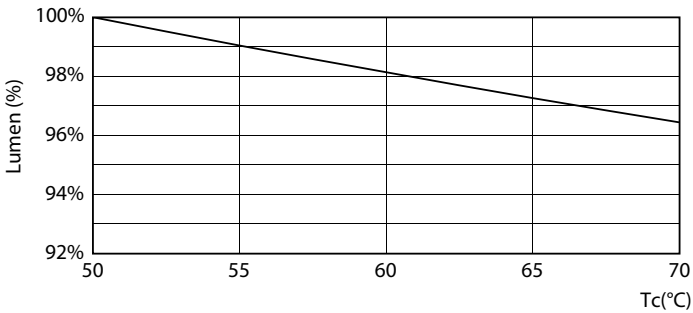

LEDtube 26W 60K LumenVsTc 2

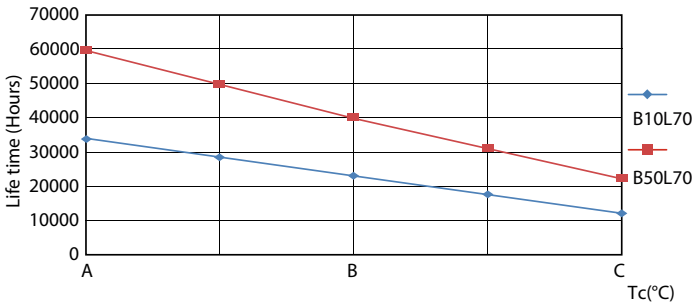


LEDtube_60K_LifetimeVsTc

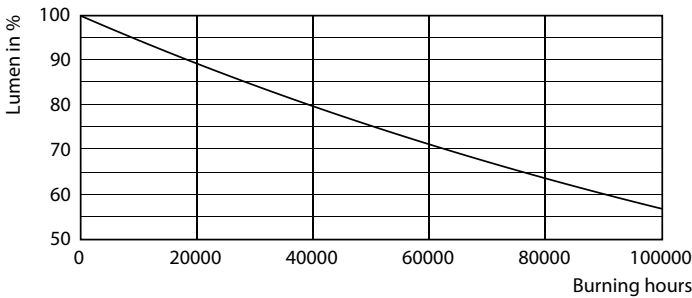

LEDtube_60K

MASTER LEDtube InstantFit HF T5

Lifetime

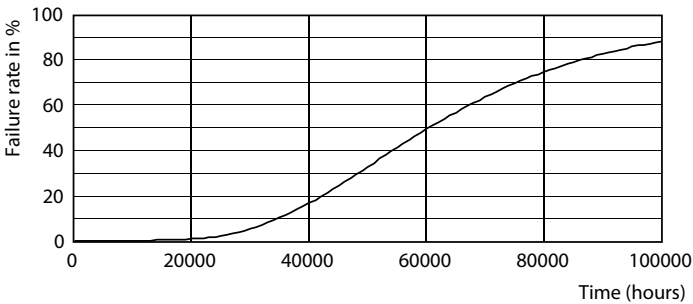

LEDtube_60K

