


Funnels




Funnels, General Purpose, Polypropylene

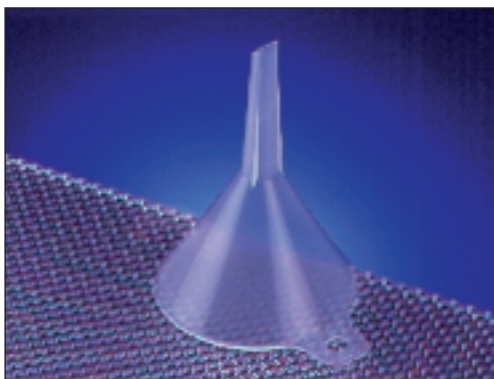

- Sturdy, break resistant funnels.
- Withstand temperatures up to 135°C.

Reference	Top i.d. mm	Stem o.d. mm	Overall height mm
FWC002	35	4	64
FWC004	65	7	97
FWC006	90	9	138
FWC008	115	11	170
FWC010	140	12	201
FWC012	165	15	221
FWC014	200	20	277

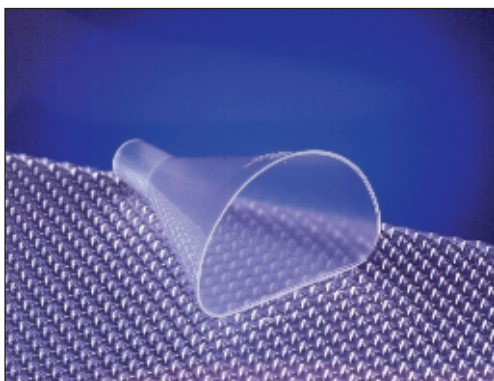


Funnels, Half Round, Polypropylene



- This shape is ideal for filling multi-neck flasks.
- Groove in the stem prevents airlocks.

Reference	Overall height mm	Taper
FWC302	80	14/23
FWC304	100	19/26
FWC306	140	29/32

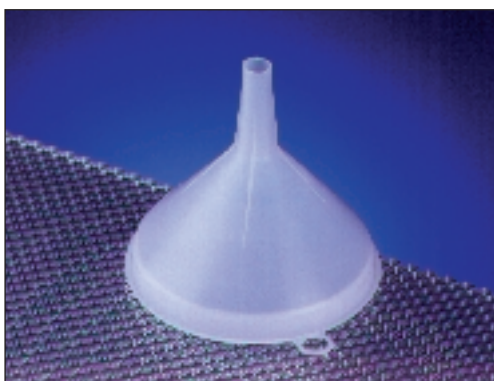

Funnels, Industrial, HDPE



- Unbreakable, rigid industrial funnels in polyethylene.
- Features straight sided upper position to prevent spillage.

Reference	Top i.d. mm	Stem o.d. mm	Overall height mm
FWC102	80	9	80
FWC104	100	11	102
FWC106	120	12	121
FWC108	140	13	141
FWC110	180	17	181
FWC112	230	21	226
FWC114	245	24	239
FWC116	290	27	277
FWC118	360	36	351