
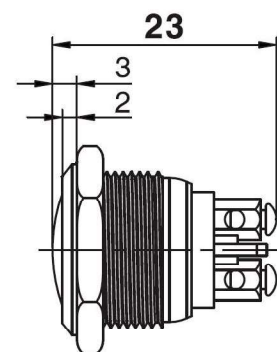




CPC # SW04825

SUPPLIER # RJS1N1S-16-B-BS-67J

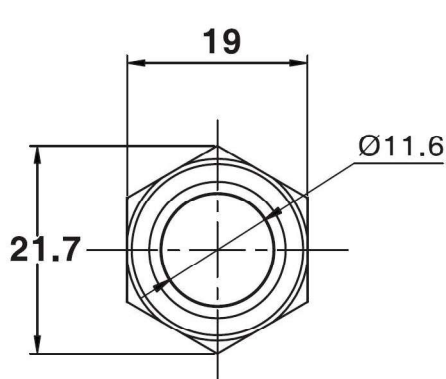

CPC # SW04826

SUPPLIER # RJS1N1S-16-F-BS-67J

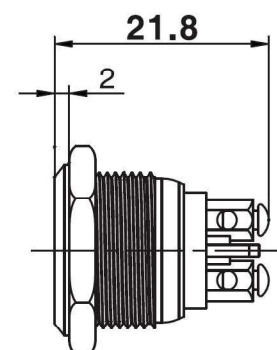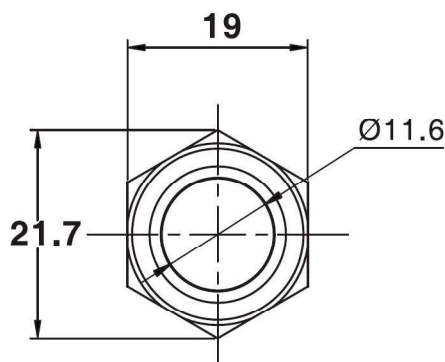

Switch Specifications

Panel Cut Out Diameter

16mm

Panel Thickness

1-10mm

Switch Function

Momentary

Circuit

1NO

The Front Shape

Flat or Ball

Terminal Type

Screw Terminals

Max. Switch Rating

2A / DC 36V

Operating Distance

2-3mm

Operating Temperature

--

Mechanical Life

1,000,000 Cycles

Electrical Life

100,000 Cycles

IP Rating

IP67