



CPC # SW04829

SUPPLIER # RJS103-22-F-BS-67J

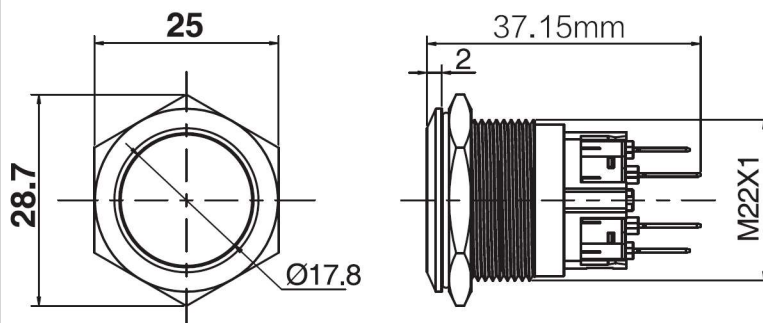

CPC # SW04830

SUPPLIER # RJS103-25-F-BS-67J

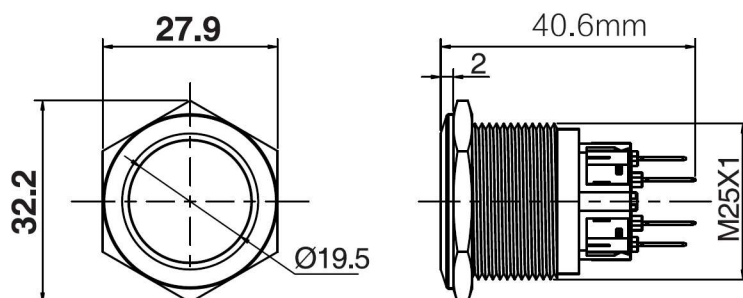

Switch Specifications

Panel Cut Out Diameter	22/25mm
Panel Thickness	1-10mm
Switch Function	Momentary
Circuit	1NO1NC
The Front Shape	Flat
Terminal Type	2.8 x 0.5mm Terminals
Max. Switch Rating	2A / DC 36V 5A / AC 250V
Operating Distance	2-3mm
Operating Temperature	--
Mechanical Life	1,000,000 Cycles
Electrical Life	100,000 Cycles
IP Rating	IP67