


CPC # SW04847	5V	(Red LED)
SUPPLIER # RJS101-19L-F-R-R-BS-5V-67Q		
CPC # SW04848	5V	(Green LED)
SUPPLIER # RJS101-19L-F-R-G-BS-5V-67Q		
CPC # SW04849	5V	(Blue LED)
SUPPLIER # RJS101-19L-F-R-B-BS-5V-67Q		
CPC # SW04850	5V	(White LED)
SUPPLIER # RJS101-19L-F-R-W-BS-5V-67Q		
CPC # SW04851	5V	(Orange LED)
SUPPLIER # RJS101-19L-F-R-O-BS-5V-67Q		
CPC # SW04852	5V POWER	(Red/Green LED)
SUPPLIER # RJS101-19L-F-C1-RG-BS-5V-67Q		

STAINLESS STEEL FINISH

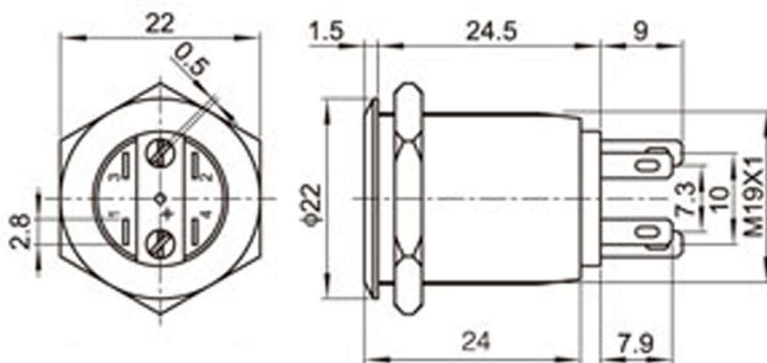

Switch Specifications

Panel Cut Out Diameter	19mm
Panel Thickness	1-10mm
Switch Function	Momentary
Circuit	1NO1NC
The Front Shape	Flat
Terminal Type	Spade Terminals
Max. Switch Rating	2A / DC 36V 5A / AC 250VAC
Operating Distance	2-3mm
Operating Temperature	--
Mechanical Life	500,000 Cycles
Electrical Life	50,000 Cycles
IP Rating	IP67