

# EXPANSION

PORTABLE DRIVE  
Data Sheet

## Seagate Expansion portable drive, add-on storage for your PC


The Seagate® Expansion portable drive is compact and perfect for taking with you on the go. Instantly add more storage space to your PC or Mac and take large files with you when you travel.

Setup is straightforward, simply connect a single USB cable and you are ready to go. The drive is powered from the USB cable, so there is no need for an external power supply. Plus, it is automatically recognised by the Windows® or Mac operating system, so there is no software to install and nothing to configure. Saving files is easy — simply drag and drop.

Take advantage of the fast data transfer speeds with the USB 3.0 interface by connecting to a USB 3.0 port.

Plus, Seagate Expansion comes with Rescue Data Recovery Services<sup>1</sup> for additional peace of mind.

1 Rescue Data Recovery Services not available in all countries.

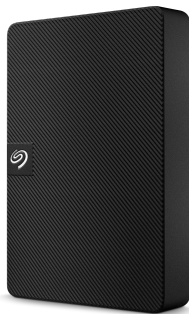



# EXPANSION

## PORTABLE DRIVE

Specifications				
Capacity 2 TB and below	Product Dimensions	Box Dimensions	Master Carton Dimensions	Pallet Dimensions
Length (in/mm)	4.539 in/115.3 mm	5.748 in/146 mm	6.142 in/156 mm	47.992 in/1,219 mm
Width (in/mm)	3.15 in/80 mm	4.134 in/105 mm	5.472 in/139 mm	40 in/1,016 mm
Depth (in/mm)	0.496 in/12.6 mm	1.26 in/32 mm	4.331 in/110 mm	46.063 in/1,170 mm
Weight (lb/kg)	0.351 lb/0.159 kg	0.527 lb/0.239 kg	2.399 lb/1.088 kg	935.399 lb/424.29 kg
Capacity 4 TB and above	Product Dimensions	Box Dimensions	Master Carton Dimensions	Pallet Dimensions
Length (in/mm)	4.539 in/115.3 mm	5.748 in/146 mm	6.732 in/171 mm	47.992 in/1,219 mm
Width (in/mm)	3.15 in/80 mm	4.134 in/105 mm	6.142 in/156 mm	40 in/1,016 mm
Depth (in/mm)	0.823 in/20.9 mm	1.575 in/40 mm	4.331 in/110 mm	46.063 in/1,170 mm
Weight (lb/kg)	0.567 lb/0.257 kg	0.75 lb/0.34 kg	3.219 lb/1.46 kg	985.422 lb/446.98 kg
Quantities				
Boxes per Master Carton	4			
Master Cartons per Pallet	384 (2 TB and below), 288 (4 TB and above)			
Pallet Layers	6			

System Requirements	What's Included
<ul style="list-style-type: none"><li>Compatible with most Windows and macOS systems. Visit <a href="https://seagate.com/os">seagate.com/os</a> for details<sup>1,2</sup></li><li>USB 3.0 port (required for USB 3.0 transfer speeds)<sup>2</sup></li></ul>	<ul style="list-style-type: none"><li>Seagate<sup>®</sup> Expansion portable hard drive</li><li>18 inch (46 cm) USB 3.0 cable</li><li>Quick start guide</li><li>Limited Warranty: AMER - 1 year, EMEA - 2 years, APAC - 3 years</li><li>Rescue Data Recovery Services<sup>3</sup></li></ul>

Region	Model Number	Capacity	Colour	UPC Code	EAN Code	Multi-Pack UPC	Notes
WW	STKM1000400	1TB	Black	763649160336	3660619040148	10763649160333	Includes Rescue <sup>3</sup>
WW	STKM2000400	2TB	Black	763649160473	3660619040247	10763649160470	Includes Rescue <sup>3</sup>
WW	STKM4000400	4TB	Black	763649160480	3660619040254	10763649160487	Includes Rescue <sup>3</sup>
WW	STKM5000400	5TB	Black	763649160497	3660619040261	10763649160494	Includes Rescue <sup>3</sup>

SEAGATE.COM

© 2021 Seagate Technology LLC. All rights reserved. Seagate, Seagate Technology, and the Spiral logo are registered trademarks of Seagate Technology LLC in the United States and/or other countries. All other trademarks or registered trademarks are the property of their respective owners. When referring to drive capacity, one gigabyte, or GB, equals one billion bytes; and one terabyte, or TB, equals one trillion bytes. Your computer's operating system may use a different standard of measurement and report a lower capacity. In addition, some of the listed capacity is used for formatting and other functions, and thus will not be available for data storage. Complying with all applicable copyright laws is the responsibility of the user. Seagate reserves the right to change, without notice, product offerings or specifications. DS2060.1 2102 GB