

5207719-4 ✓ ACTIVE

AMPLIMITE | AMPLIMITE Kit

TE Internal #: 5207719-4


AMPLIMITE Kit, D-Sub Locking & Mounting, Female Screwlock

Assembly Kit, Screw Length .748 in [18.99 mm]

[View on TE.com >](#)



Connectors > D-Shaped Connectors > D-Sub Accessories > Locking & Mounting

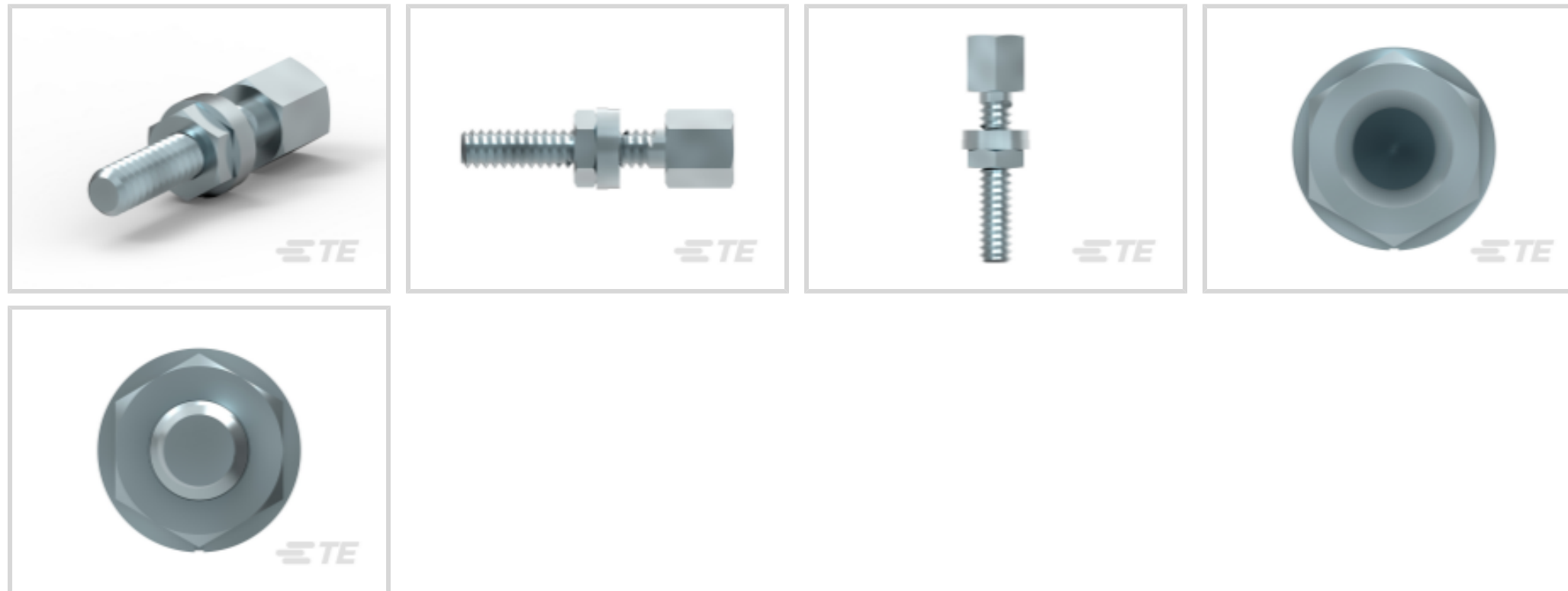

D-Shaped Connector Accessories: **Female Screwlock Assembly Kit**

Screw Length: 18.99 mm [.748 in]

Features

Product Type Features

Product Type	Accessory
D-Shaped Connector Accessories	Female Screwlock Assembly Kit

Mechanical Attachment

Screw Plating Material	Zinc
Screwlock Style	Screwlock with Lockwasher and Hex Nut
Screw Material	Cold Rolled Steel
Screw Finish	Clear Chromate
Screw & Hole Thread Size	4-40
Screw Length	18.99 mm [.748 in]

Dimensions

Thread Length	14.22 mm [.56 in]
---------------	-------------------

Operation/Application

For Use With	All Plastic Connectors with Integral Standoffs (HD or HDF)
--------------	--

Packaging Features

Packaging Quantity	500
Packaging Method	Bag, Kit

Product Compliance


[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	<p>Current ECHA Candidate List: JUL 2021 (219)</p> <p>Candidate List Declared Against: JUL 2021 (219)</p> <p>SVHC > Threshold:</p> <p>Pb (.35% in Component Part)</p> <p>Article Safe Usage Statements: Do not eat, drink or smoke when using this product. Wash thoroughly after handling. Recycle if possible and dispose of the article by following all applicable governmental regulations relevant to your geographic location.</p>
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

 <p>TE Part # 5207719-2 FEMALE SCREWLOCK KIT,BULK PKG</p>	 <p>TE Part # 1-1437012-0 609-003=HDW IDC JCKSOCKET ASSY</p>	 <p>TE Part # 5207720-3 FEMALE SCREWLOCK,ZN</p>
--	---	--

Also in the Series | **AMPLIMITE Kit**

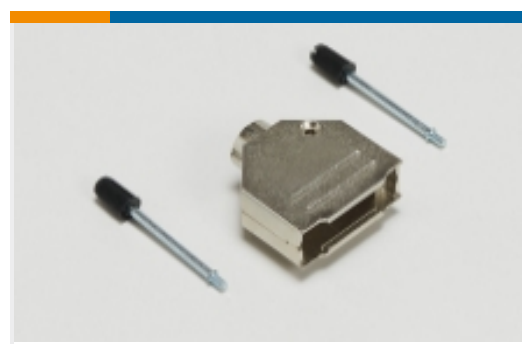

D-Sub Backshells & Clamps(136)



D-Sub Contact Accessories(1)



D-Sub Covers(3)




D-Sub Locking & Mounting(122)


Customers Also Bought



TE Part #1658539-5
PIN CONT DUPL PLT STRIP HD-20

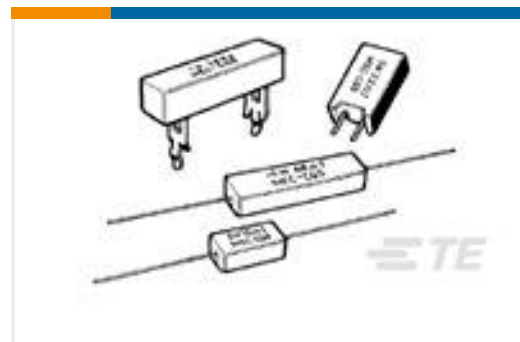


TE Part #2-1623779-1
SQB20 68R 5% (WIRE)

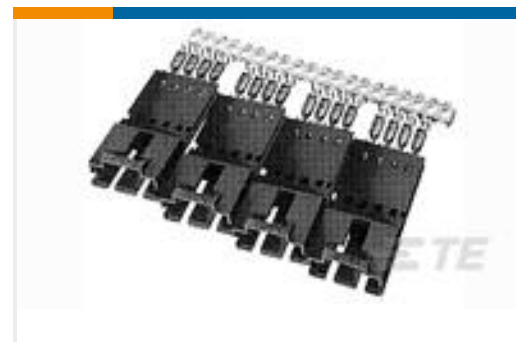

TE Part #103945-2
5X3 MTE SHRD PIN SR LATCH .100



TE Part #1-745266-1
D-Sub Connector Contacts: Pin,
Phosphor Bronze, Signal, Size 20

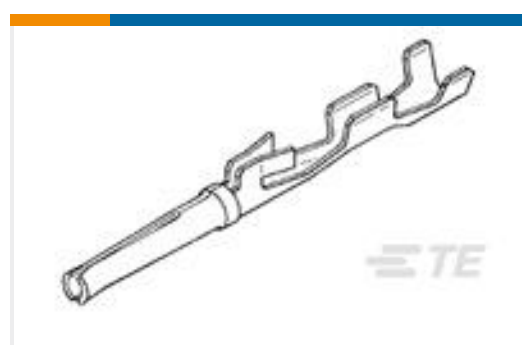


TE Part #1-745269-1
CONT, SOCKET, HDE, #22-26



TE Part #87133-8
06 LOCKING CLIP HSG DR MRKD



TE Part #1-794222-0
MINI UMNL2 PIN 20-16AWG AU LF

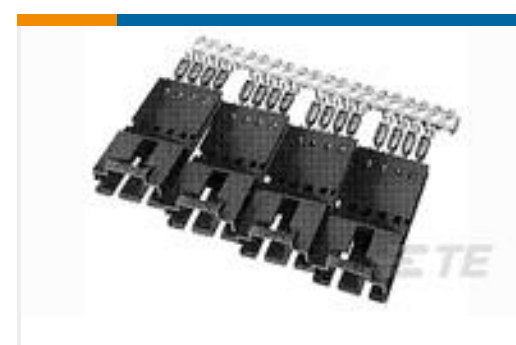

TE Part #103945-1
8X2 MTE SHRD PIN SR LATCH .100



TE Part #171505-3
PIDG RING UL.CSA(22-18)

Documents

Product Drawings

FEMALE SCREWLOCK KIT, BULK PKG

English

CAD Files

Customer View Model

ENG_CVM_CVM_5207719-4_O.2d_dxf.zip

English

3D PDF



3D

Customer View Model

[ENG_CVM_CVM_5207719-4_O.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_5207719-4_O.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[AMPLIMITE Subminiature D Connectors - Cable Connectors](#)

English

[AMPLIMITE Cable Connectors and Shielding Hardware Kits QRG](#)

English

Product Environmental Compliance

[TE Material Declaration](#)

English

Instruction Sheets

[Instruction Sheet \(U.S.\)](#)

English