



Digital Micrometer 0-25mm, w/o Data Output

Item number: 293-821-30



Description


This Standard Digimatic Micrometer is an affordable device that offers the following benefits:

- It is cost-effective with simplified functionality for standard applications.
- Extraordinary battery life of 2,4 years. Without data output.
- Constant measuring force

Features

Range:	0 - 25 mm
Digital step:	0,001 mm
Maximum Permissible Error J MPE:	±2 μm
Measuring force:	5 - 10 N
Mass:	275 g
Data output:	Yes
Display:	LCD, character height 7.5 mm
Measuring face:	Carbide-tipped, micro-lap finish
Measuring spindle:	ø6,35 mm, spindle pitch 0,5 mm
Scale:	Thimble and sleeve satin chrome finish, ø18 mm
Power supply:	1 battery SR-44
Battery life:	Approx. 2,4 years
Digital/Analog:	Digital
Inch-Metric:	Metric
Measuring spindle:	ø6,35 mm, spindle pitch 0,5 mm
Battery life:	Approx. 2,4 years
Delivered:	Including box, key, 1 battery, certificate of inspection

Dimensions

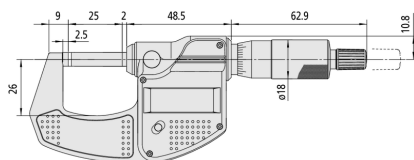

Spare parts

Consumable spares:

Battery SR44 1.5V



938882