

Subminiature D Connectors for Cable Mounting

This guide illustrates the preferred range of Subminiature D Connectors for cable mounting.

Please refer to our general catalogs or our website www.tycoelectronics.com for details of additional

ranges, connector styles, plating options and performance levels.

Standard Density Crimp Termination

Connector Housings

Material and Finish:

Front Shell—Steel, tin plated

Housing—Black glass-filled thermoplastic


Flammability—UL 94V-0

Current Rating—3.7A max.

Insulation Resistance—5000 MΩ min.

Dielectric Strength—1000V AC min.

Temperature Rating—-55°C to +105°C

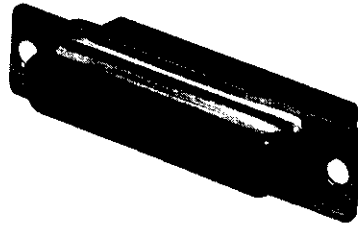

Plug Connector Housing

No of Ways	Part Number
9	167292-1
15	167293-1
25	167294-1
37	167295-1
50	167296-1

Socket Connector Housing

No of Ways	Part Number
9	164531-4
15	164532-4
25	164533-4
37	164534-4
50	164535-4

Crimp Contacts


Material and Finish:

Contact Material—

Pin—Brass

Socket—Phosphor bronze

Contact Area Plating—0.76µm Gold

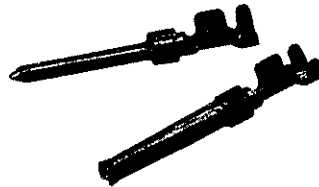

Male Contact for Plug Connector Housing

Wire Size	Reel of 12500 Contacts (1)	Reel of 500 Contacts (2)	Bag of 100 Loose Contacts (3)
20-24 AWG	166053-1	5-166053-1	166293-1
24-28 AWG	166054-1	5-166054-1	166294-1

Female Contact for Socket Connector Housing

Wire Size	Reel of 12500 Contacts (1)	Reel of 500 Contacts (2)	Bag of 100 Loose Contacts (3)
20-24 AWG	166051-1	5-166051-1	166291-1
24-28 AWG	166052-1	5-166052-1	166292-1

Application Tooling

- (1) Reel of 12500 Contacts** Use applicator Part Number 1238049 with suitable press.
- (2) Reel of 500 Contacts** Use Mini Reel-Fed CERTI-LOK (Hand tools for applying and/or extracting electrical connectors) Part Number 169424-1
- (3) Loose Piece Contacts**
 - Premium:** Use CERTI-CRIMP II (Hand compression electrical connector crimping tools) — Part Number 91503-1
 - Commercial:** Use SDE die — Part Number 58448-2 with suitable ancillary equipment
- Insertion / Extraction Tool** Use Part Number 1579007-9

Subminiature D Connectors for Cable Mounting