

# EAO – Your Expert Partner for Human Machine Interfaces

82-5153.2123 - Illuminated pushbutton 19 mm stainless-steel, maintain

## 82-5153.2123 - Illuminated pushbutton 19 mm stainless-steel, maintain



Attention: The preview is based on a sample product. This can differ from your current configuration.

### Mounting

Mounting cut-out Ø 19 mm  
Design flush

### Front

Front dimension Ø 22 mm  
Front shape round  
Front ring shape flush  
Front bezel material Stainless steel

### Other Attributes

Operating voltage 12 V AC/DC  
Weight 0,018 kg  
Operation current 7 mA

### Operating-/Indication part

Lens optics opaque  
Lens material Stainless steel  
Lens profile flat  
Lens illumination illuminative  
Lens colour Stainless steel

### IP-Rating

Front protection IP65, IP67

### Connection Method

Terminal Solder 2.8 x 0.5 mm

### Actuator

Switching action Maintained

### Switching element

Switching current 0.2 A  
Contact material gold-plated silver  
Contacts 1 C  
Switching system Snap-action switching element  
Switching voltage 24 V AC/DC

### Illumination

Illumination Ring with blue LED

### Function

Illuminated pushbutton

# EAO – Your Expert Partner for Human Machine Interfaces

82-5153.2123 - Illuminated pushbutton 19 mm stainless-steel, maintain


## Dimensions



## Mounting cut-outs



## Wiring diagram

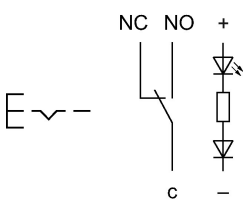

## Component layout



## Legend

Switching action: C = Maintained  
Contacts: C = Changeover