



Pushing Performance

HARTING Product Change Notification

PCN

Product range: Inducom

PCN/21/007/C+N/US

Title: Change to InduCom Hoods

Date: 04/12/2021

Page 1/3

Dear Customer,


We have made a minor change to the Inducom hoods

1. Concerned Part Numbers:

See list on page 3.

2. Description of change:

At the end of 2019 HARTING changed the design of the Inducom hoods. At the outer side of the hoods a 2nd slit was added (see picture below). This slit was intended for use with a mechanical coding option to be launched in the future. Please be informed, that HARTING will eliminate this 2nd slit. With this change the overall length of the hoods will be reduced to the same dimension as the pre-2019 design

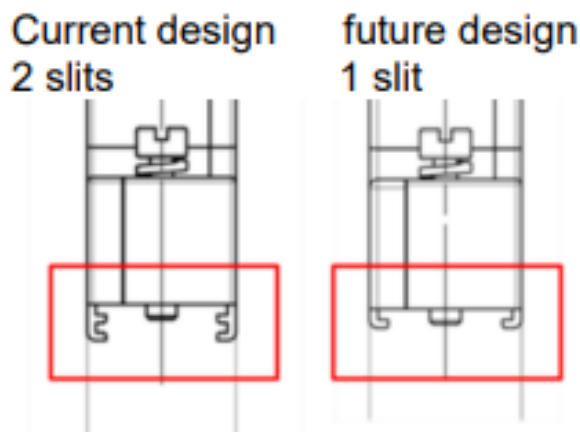

When the new coding system is introduced we will create separate part numbers for the corresponding hoods with two slits.



Pushing Performance

HARTING Product Change Notification

PCN

PCN/21/007/C+N/US

Date: 04/12/2021

Page 2/3

3. Impact on product specification

The functional characteristics will remain unchanged and the new generation will be backward compatible with the today's versions.

4. Scheduled date of implementation

The 1 slit types will be produced from 2021/10/01.

5. Identification of change

Part numbers will remain unchanged, only the revision level will be changed.

6. Data sheet

With the delivery of the new versions, the following technical data will be updated in the HARTING e-catalogue accordingly:

- Data-sheets
- Type-sheets (2D drawings)
- 3D models

Regards,

Phill Shaw

HARTING Inc

Senior Product Manager

E-Mail: phillip.shaw@HARTING.com

<http://www.HARTING.com>



Pushing Performance

HARTING Product Change Notification

PCN

PCN/21/007/C+N/US

Date: 04/12/2021

Page 3/3

List of Affected Part Numbers

Part Number	Description	Part Number	Description
61030010010	Full metal hood 9P T&S entry K scr 4-40	61030012010010	Full metal hood 9P T&S entry H scr 4-40
61030010010010	Full metal hood 9P T&S entry K scr 4-40	61030012013	InduCom 9P hood S40° w GB H scr 4-40
61030010013	InduCom 9P hood S40° w GB K scr 4-40	61030012013010	InduCom 9P hood S40° w/o GB H scr 4-40
61030010013010	InduCom 9P hood S40° w/o GB K scr 4-40	61030012014	InduCom 15P hood S40° w GB H scr 4-40
61030010014	InduCom 15P hood S40° w GB K scr 4-40	61030012014010	InduCom 15P hood S40° w/o GB H scr 4-40
61030010014010	InduCom 15P hood S40° w/o GB K scr 4-40	61030012015	InduCom 25P hood S40° w GB H scr 4-40
61030010015	InduCom 25P hood S40° w GB K scr 4-40	61030012015010	InduCom 25P hood S40° w/o GB H scr 4-40
61030010015010	InduCom 25P hood S40° w/o GB K scr 4-40	61030012016	Full metal hood 15P T&S entry H scr 4-40
61030010016	Full metal hood 15P T&S entry K scr 4-40	61030012016010	Full metal hood 15P T&Sentry H scr4-40-S
61030010016010	InduCom9 15-p full metal hood top entry	61030012017	Full metal hood 25P T&S entry H scr 4-40
61030010017	Full metal hood 25P T&S entry K scr 4-40	61030012017010	INDUCOM - 25 poles, full metal hood
61030010017010	Full metal hood 25P T&S entry K scr 4-40	61030012018	Full metal hood 37PT&S entry H scr 4-40
61030010018	Full metal hood 37PT&S entry K scr 4-40	61030012018010	InduCom 37P top side entry hood w/o
61030010018010	InduCom 37P top side entry hood w/o	61030012019	Full metal hood 50P T&S entry H scr 4-40
61030010019	Full metal hood 50P T&S entry K scr 4-40	61030012019010	InduCom 50P top side entry hood w/o
61030010019010	InduCom 50P top side entry hood w/o	61030012110	InduCom 9-pole easy access hood with ine
61030010110	InduCom 9-pole easy access hood with ine	61030012110010	InduCom 9-pole easy access hood without
61030010110010	InduCom 9-pole easy access hood without	61030012116	InduCom 15-pole easy access hood with in
61030010110283	InduCom 9p easy access hood assembly	61030012116010	InduCom 15-pole easy access hood without
61030010116	InduCom 15-pole easy access hood with in	61030012117	InduCom 25P w ground block hexag 4-40UNC
61030010116010	InduCom 15-pole easy access hood without	61030012117010	InduCom 25P w/o ground block hex 4-40UNC
61030010117	InduCom 25P w ground block knur 4-40UNC	61030013010	Full metal hood 9P T&S entry K scr M3
61030010117010	InduCom 25P w/o ground block knu 4-40UNC	61030013010010	Full metal hood 9P T&S entry K scr M3
61030011010	Full metal hood 9P T&S entry H scr M3	61030013010013	Ind. 9P top entry hood with M3x37 knur.
61030011010010	Full metal hood 9P T&S entry H scr M3	61030013013	InduCom 9P hood S40° w GB K scr M3
61030011013	InduCom 9P hood S40° w GB H scr M3	61030013013010	InduCom 9P hood S40° w/o GB K scr M3
61030011013010	InduCom 9P hood S40° w/o GB H scr M3	61030013014	InduCom 15P hood S40° w GB K scr M3
61030011014	InduCom 15P hood S40° w GB H scr M3	61030013014010	InduCom 15P hood S40° w/o GB K scr M3
61030011014010	InduCom 15P hood S40° w/o GB H scr M3	61030013015	InduCom 25P hood S40° w GB K scr M3
61030011015	InduCom 25P hood S40° w GB H scr M3	61030013015010	InduCom 25P hood S40° w/o GB K scr M3
61030011015010	InduCom 25P hood S40° w/o GB H scr M3	61030013016	Full metal hood 15P T&S entry K scr M3
61030011016	Full metal hood 15P T&S entry H scr M3	61030013016010	InduCom9 15-p full metal hood top entry
61030011016010	Full metal hood 15P T&S entry H scr M3	61030013017	Full metal hood 25P T&S entry K scr M3
61030011017	Full metal hood 25P T&S entry H scr M3	61030013017010	INDUCOM - 25 poles, full metal hood
61030011017010	INDUCOM - 25 poles, full metal hood	61030013018	Full metal hood 37PT&S entry K scr M3
61030011018	Full metal hood 37PT&S entry H scr M3	61030013018010	InduCom 37P top side entry hood w/o
61030011018010	InduCom 37P top side entry hood w/o	61030013019	Full metal hood 50P T&S entry K scr M3
61030011019	Full metal hood 50P T&S entry H scr M3	61030013019010	InduCom 50P top side entry hood w/o
61030011019010	InduCom 50P top side entry hood w/o	61030013110	InduCom 9-pole easy access hood with ine
61030011110	InduCom 9-pole easy access hood with ine	61030013110010	InduCom 9-pole easy access hood without
61030011110010	InduCom 9-pole easy access hood without	61030013116	InduCom 15-pole easy access hood with in
61030011116	InduCom 15-pole easy access hood with in	61030013116010	InduCom 15-pole easy access hood without
61030011116010	InduCom 15-pole easy access hood without	61030013117	InduCom 25P w ground block knur M3
61030011117	InduCom 25P w ground block hexagonal M3	61030013117010	InduCom 25P w/o ground block knurled M3
61030011117010	InduCom 25P w/o ground block hexag M3	61030015010	Ind. 9P top side entry hood with M2 .6
61030012010	Full metal hood 9P T&S entry H scr 4-40		