

Universal Car charger

CNE-CCA01
Quick Guide v 1.1

EN

User manual.

Features: Universal Car charger

- Built-in IC chip and safety fuse
- Over-load, over-voltage, over-heated, over-current and short circuit protection
- Smart Intelligent Chip
- Input Voltage: DC 12-24 V
- Output Voltage& Current: DC 5 V- 1000 mA, Max.
- Quantity of USB ports: 1

- Operating temperature: 0 - 40°C
- Storage temperature: - 20°C to 60°C
- Dimension: 51.8*31.2*26.2 mm (L*W*D)
- Weight: 0.016 g
- Compatible with Smartphone/Mobile Phone/GPS/Camera/MP3/MP4/PDA etc. OS Android/Windows

Package contents	Connection
Car charger User Manual	This product is intended for devices that use Micro-USB cables. Plug this connector into a car power outlet and make sure that the power source has the correct installation and voltage requirements. Then you can charge any devices that can be charged via Micro-USB cables




SAFETY INSTRUCTIONS

Read carefully and follow all instructions before using this product.

1. Do not expose the mouse to excessive moisture, water or dust. Do not install in rooms with high humidity and dust level.
2. Do not expose the mouse to heat: do not place it close to heating appliances, and do not expose it to direct sun rays.
3. The product shall be connected to the power supply source of the type indicated in the operation manual only.
4. Never spray liquid detergents. Use only dry clothes for device cleaning.

WARNING

1. It is forbidden to dismantle the device. Attempt to repair this device is not recommended and leads to cancellation of the warranty.
 2. Choose a charger with a cable that is compatible with your device.
- If the actions from the above list do not contribute to problem solving, please contact the support team at Canyon: <http://canyon.eu/ask-your-question>

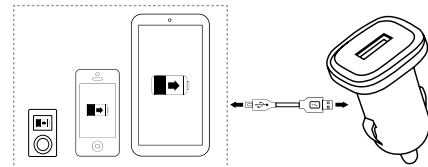

Warranty

- BG:** За повече информация относно гаранционните условия, моля посетете: <http://canyon.bg/ogranicheniya-na-garantsiyata/>
- HU:** A részletes garanciális információk megtekintéséhez látogasson el a <http://hungary.canyon.eu/a-korlatozott-jotallas/>

PL: Szczegółowe informacje na temat warunków gwarancji można znaleźć w: <http://canyon.eu/warranty-terms/>

RO: Pentru condițiile specifice de garanție, vizitați: <http://canyon.ro/garanție-produce/>

SK: Viac informácií o záručných podmienkach je uvedených na internetovej stránke <http://canyon.eu/warranty-terms/>

canyon.sk/prehlasenia-o-zaruke/
SI: Podrobne informacije o garancijskih pogojih najdete na strani: <http://canyon.eu/warranty-terms/>
RS: Za detaljnije informacije o uslovima garancije obratite se: <http://canyon.eu/warranty-terms/>

LV: Detalizēta informācija par garantijas noteikumiem atrodamā: <http://canyon.eu/warranty-terms/>
LT: Detalesnė informacija apie garantijų sąlygas rasite tinklalapyje: <http://canyon.eu/warranty-terms/>
EE: Detailse info garantiitingimuste kohta leiate: <http://canyon.eu/warranty-terms/>



All other products names and trademarks are property of their respective owners
 Vice informáci na www.canyon.eu/certificates. Certificats disponibles sur www.canyon.eu

www.canyon.eu

WARRANTY

The warranty period starts from the day of the product purchase from Canyon authorized Seller. The date of purchase is the date specified on your sales receipt or on the waybill. During the warranty period, repair, replacement or refund for the purchase shall be performed at the discretion of Canyon. In order to obtain warranty service, the goods must be returned to the Seller at the place of purchase together with proof of purchase (receipt or bill of lading). 2 years warranty from the date of purchase by the consumer. The service life is 2 years. Additional information about the use and warranty is available at <https://canyon.eu/warranty-terms/>

Date of manufacture: (see at the package). Made in China.

Manufacturer: Asbisc Enterprises PLC, 43, Kolonakiou Street, Diamond Court 4103 Ayios Athanasios <http://canyon.eu>