

Appliance 25W E14 230-240V T25 CL OV 1CT

Product family description
Tubular vacuum lamps with clear glass (T-bulb)

Product Features

- Coiled-coil filament
- Manufactured with heat-resistant solder, getter and lamp-base cement

Product Benefits

- Reliable operation when used in special lampholders at high oven temperatures (up to 300°C)

Application


- Electrical and standard ovens, rotisseries and similar places subject to high operating temperatures
- Available for specific oven luminaires fitted in different positions such as downlighter, side-light and backlight

Product data	
Order code	038715 50
Full product code	871150003871550
locod	
Full product name	Appliance 25W E14 230-240V T25 CL OV 1CT
Order product name	App 25W E14 230-240V T25 CL OV 1CT
Packing type	1 Lamp in a Folding Carton
Pieces per pack	1
Packing configuration	10X10F
Packs per outerbox	100
Bar code on pack - EAN1	8711500038715
Bar code on intermediate packing - EAN2	8711500255419
Bar code on outerbox - EAN3	8711500257918
Logistic code(s) - 12NC	9241 982 44440
ILCOS code	IBT/C-25-230/240-E14-25*
Net weight per piece	10.500 GR
Successor order code	
Cap-Base	SES
Bulb	T25 [T 25mm]


Product data	
Bulb Finish	Clear
Execution	-
Burning Position	any [Any/Universal]
Main Application	Oven
Average Lifetime	1000 hr
Rated Lamp Wattage	25W
Voltage	230-240V
Energy Efficiency Label (EEL)	F
Lamp Luminous Flux	172 Lm




App E14 T25 CL

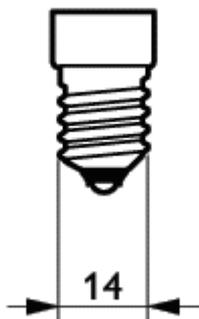

Cap-Base SES

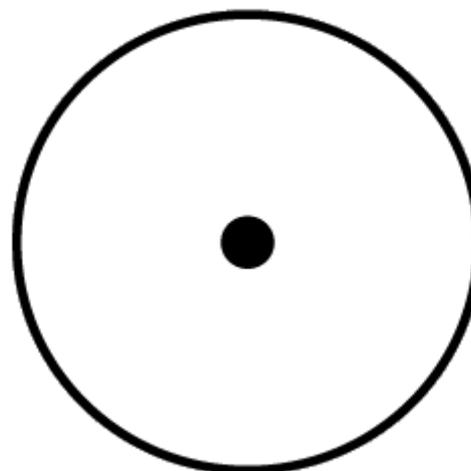

Burning Position any

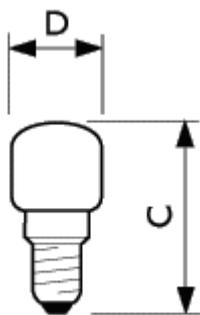

App E14 T25

	C	D
Full product name	Max	Nom
Appliance 25W E14 230-240V T25 CL OV ICT	57	25

