

# OMEGALABEL® Temperature Monitors

## Series 21

- ✓ Single Temperature Point Per Label
- ✓ Compact Size
- ✓ Easy to Use
- ✓ Sold in Packs of 10 (21 Per Sheet)

### Fast, Easy-To-Use Temperature Monitoring System

OMEGALABEL® is a self-adhesive temperature monitor consisting of a heat-sensitive indicator sealed under a transparent heat-resistant window. The indicator circle turns to light gray or black at the temperature rating shown on the card. Color change is not reversible and provides a temperature history of the surface being monitored. To serve as a permanent record, the OMEGALABEL® can be removed and attached to an inspection report.


### Guaranteed Accuracy and Reliability

OMEGALABEL® accuracy is guaranteed to be within  $\pm 2\%$ .

The Series 21 OMEGALABEL® is conveniently mounted on sheets (21 per sheet) for fast, on-the-spot application by just peeling them off one at a time. The adhesive backing easily adheres to any clean, dry surface.

### Requirements Estimator

Packs	Sheets	Labels
1 Pack	10	210
3 Packs	30	630
5 Packs	50	1050
10 Packs	100	2100
20 Packs	200	4200
30 Packs	300	6300
50 Packs	500	10500

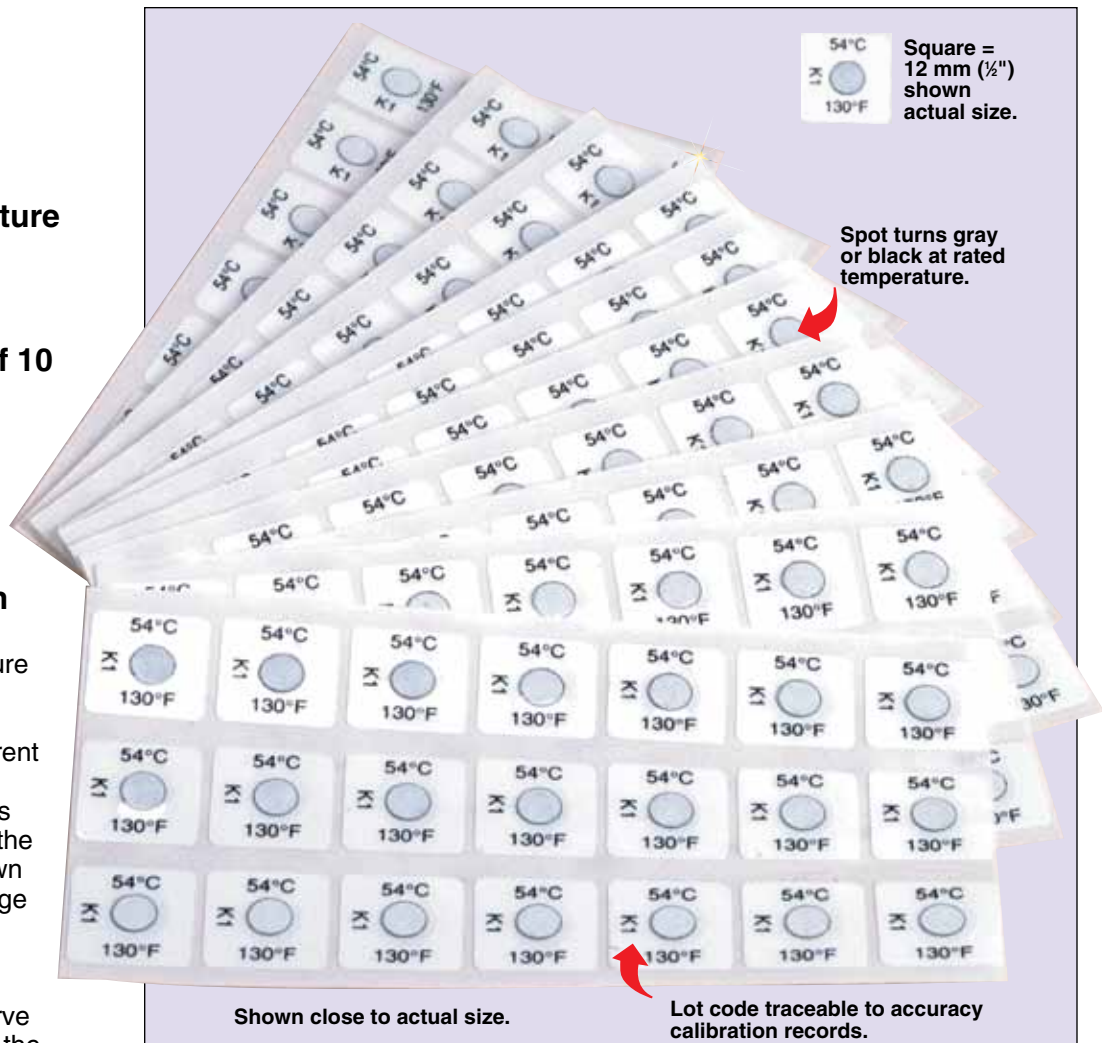

### To Order Visit [omega.com/21\\_labels](http://omega.com/21_labels) for Pricing and Details

Model No.	Range	Model No.	Range
21-100	38°C (100°F)	21-220	104°C (220°F)
21-110	43°C (110°F)	21-230	110°C (230°F)
21-120	49°C (120°F)	21-240	116°C (240°F)
21-130	54°C (130°F)	21-250	121°C (250°F)
21-140	60°C (140°F)	21-260	127°C (260°F)
21-150	66°C (150°F)	21-270	132°C (270°F)
21-160	71°C (160°F)	21-280	138°C (280°F)
21-170	77°C (170°F)	21-290	143°C (290°F)
21-180	82°C (180°F)	21-300	149°C (300°F)
21-190	88°C (190°F)	21-400	204°C (400°F)
21-200	93°C (200°F)	21-500	260°C (500°F)
21-210	99°C (210°F)		

**Ordering Example:** 21-500, 1 pack of labels (10 sheets, 210 labels) with a temperature range of 260°C (500°F).

**Notes:** All temperatures can be combined for quantity pricing.

Dot dimension: 4.8 mm ( $\frac{3}{16}$ " diameter).

Individual label: 12 mm ( $\frac{1}{2}$ " square).

Standard packaging: 10 sheets of one temperature per pack.