



Key Features

- 220-240V
- Contemporary styling
- Ceiling or wall mounted
- 350° rotation



Class 1




0.19kg

HARVEY

Spotlight

Code	Finish	Description	Lamp	Dimensions
INL-31775-SNIC	Satin Nickel	Harvey Spotlight	1 x 35W Max GU10	L:100mm W:85mm H:120mm
INL-31775-BLK	Black			
INL-31775-WHT	White			
INL-31775-SATBRS	Satin Brass			

NEW

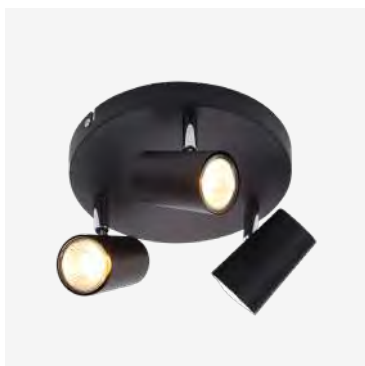

Key Features

- 220-240V
- Contemporary styling
- Adjustable lamps
- 350° rotation



Class 1



0.62kg

HARVEY

3 Light Spotlight

Code	Finish	Description	Lamp	Dimensions
INL-31776-SNIC	Satin Nickel	Harvey 3 Light Spotlight	3 x 35W Max GU10	Dia:215mm H:120mm
INL-31776-BLK	Black			
INL-31776-WHT	White			
INL-31776-SATBRS	Satin Brass			

 
NEW



NEW
COLOUR
OPTION

Key Features

- 220-240V
- Contemporary styling
- Adjustable lamps
- 350° rotation



Class 1 0.75kg

HARVEY
4 Light Bar Spotlight

Code	Finish	Description	Lamp	Dimensions
INL-31723-SNIC	Satin Nickel	Harvey 4 Light Bar Spotlight	4 x 35W Max GU10	L:774mm W:85mm H:120mm
INL-31723-BLK	Black			
INL-31723-WHT	White			
INL-31723-SATBRS	Satin Brass			

NEW