

## 113A.6C | 113A.C - Chromed adjustable wrenches




### Standards:

NF ISO 6787, ISO 6787, DIN 3117, ASME B107.100

### Description:

- Good access to the button = easy setting.
- Non-protruding moving jaw at maximum capacity.
- Pre-adjustment of jaw opening thanks to millimetric gradation.
- Right-hand button rotation.
- Range from 4" to 24".
- Presentation: chromed body and polished head faces.

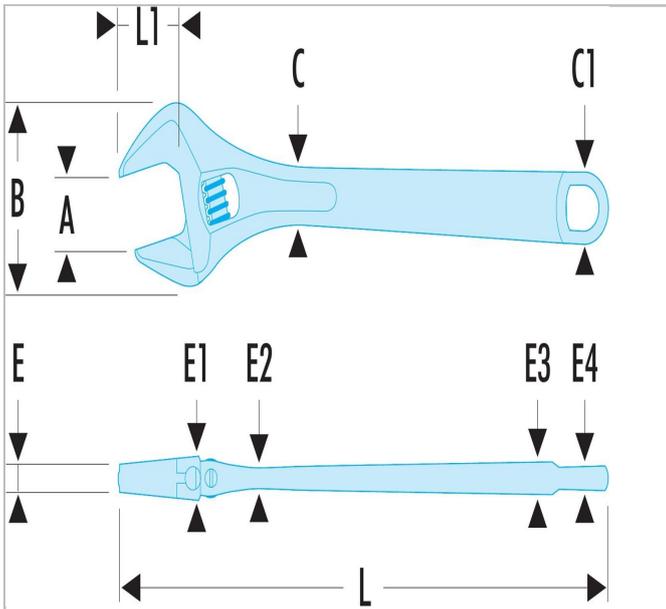

	<b>113A.6C</b>
A [mm]	20.0
Length L [mm]	155.0
Length L1 [mm]	19.0
Thickness E [mm]	5.0
Thickness E1 [mm]	11.8
Thickness E2 [mm]	6.0
Thickness E3 [mm]	8.3
Thickness E4 [mm]	5.8
Head Height C [mm]	14.8
Head Height C1 [mm]	18,5
Head Width B [mm]	45.0
Weight [Kg]	0.125