



## 251A - Precision sleeved drift punches



### Description:

- The centre slides within a guide to prevent distortion, even in smaller sizes.
- Shank hardened to 52 to 57 HRc.
- Zinc-plated body, burnished body.

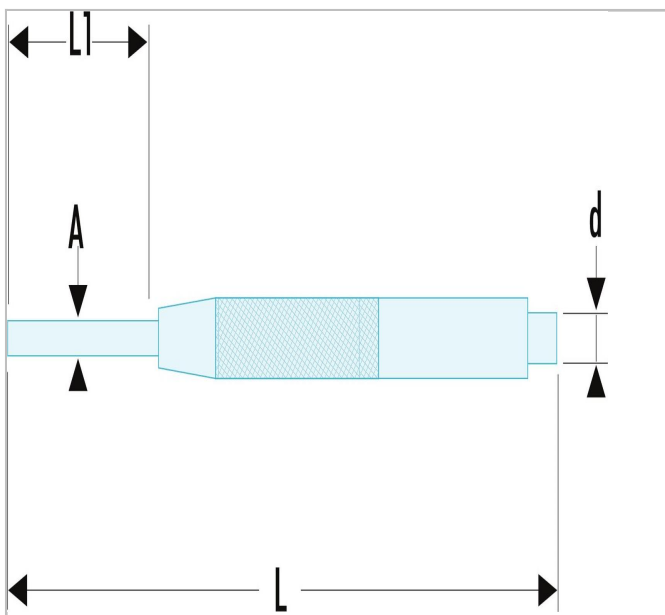

	A [mm]	A [in]	Diameter [mm]	Length L [mm]	Length L1 [mm]	Weight [g]
<b>251A.1</b>	0.9		3.0	70.0	14.0	5.0
<b>251A.1.5</b>	1.4		3.5	83.0	21.0	10.0
<b>251A.2</b>	1.9		3.5	88.0	26.0	10.0
<b>251A.2.5</b>	2.4		4.5	93.0	22.0	18.0
<b>251A.3</b>	2.9		4.5	93.0	22.0	20.0
<b>251A.3.5</b>	3.4		5.5	96.0	25.0	25.0
<b>251A.4</b>	3.9		5.5	96.0	28.0	30.0
<b>251A.5</b>	4.9		7.0	107.0	33.0	45.0
<b>251A.6</b>	5.9		9.0	112.0	36.0	65.0