

256.4 | 256 - Precision centre punches





Standards:

NF E 71-211, DIN 7250, ASME B107.410

Description:

- Chrome-vanadium steel forged, hardened to 52 to 58 HRc.
- Presentation: knurled body.
- Zinc-plated finish.

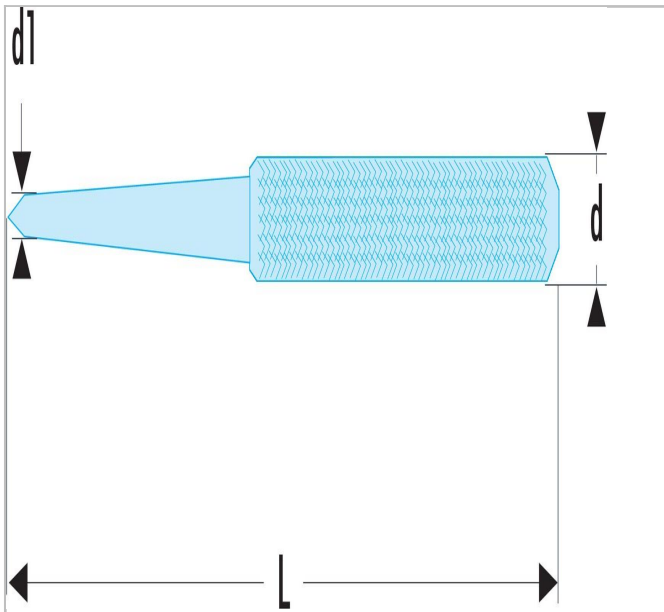

| | |
|--|--------------|
|  | 256.4 |
| A [mm] | 4.0 |
| Length L [mm] | 105.0 |
| Diameter [mm] | 8.0 |
| Weight [g] | 35.0 |