

## 39.4H | 39 - Metric short-reach combination wrenches





### Standards:

NF ISO 691, NF ISO 7738, NF ISO 3318, NF ISO 1711-1, E74-306, ISO 691, ISO 7738, ISO 3318, ISO 1711-1, DIN ISO 691, DIN 1711-1, ASME B107.100

### Description:

- Short combination wrenches: the short handle and compact head allow for high handiness. Ideal for confined access.
- OGV® profile with 12-point ring for powerful tightening while protecting the nut. H suffix = 6-point ring.
- Ring head angled at 15°.
- Open end head angled at 15°.
- Metric sizes: 3.2 to 17 mm.
- Presentation: satin chrome finish.

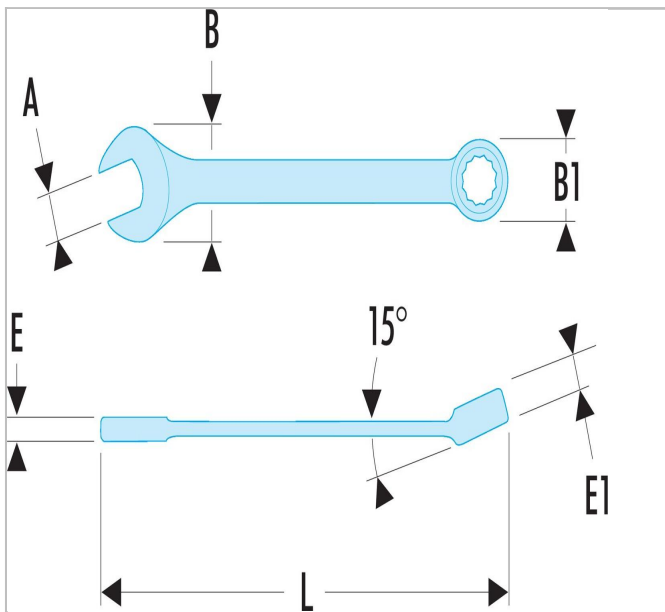

	<b>39.4H</b>
A [mm]	4.0
Length L [mm]	77.0
Thickness E [mm]	3.1
Thickness E1 [mm]	3.1
Head Width B [mm]	10.0
Weight [Kg]	0.01
Hex Size [mm]	6.0