



405.10MT | Micro-Tech® "rugged" cutters: versatility



Description:

- These pliers allow neat cutting of multiple materials: from copper wire to piano wire up to 0.5 mm.
- Fall prevention models avoid wire ejection.

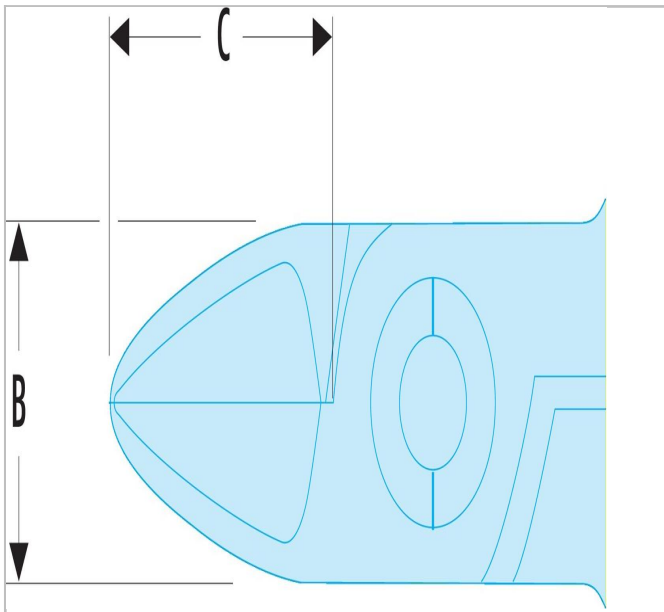

|  | 405.10MT |
|--|-----------|
| Length L [mm] | 110.0 |
| Thickness E [mm] | 7.0 |
| Head Height C [mm] | 11.5 |
| Head Width B [mm] | 10.5 |
| Cu - Ni Diameter [mm] | 0.3 - 1.4 |
| Cut ["] | h |
| Fe Wire 30 HRc Diameter [mm] | 0.8 |
| Piano Diameter [mm] | 0.5 |
| Weight [g] | 60.0 |