



405.10RMT | Micro-Tech® "rugged" cutters: versatility



Description:

- These pliers allow neat cutting of multiple materials: from copper wire to piano wire up to 0.5 mm.
- Fall prevention models avoid wire ejection.

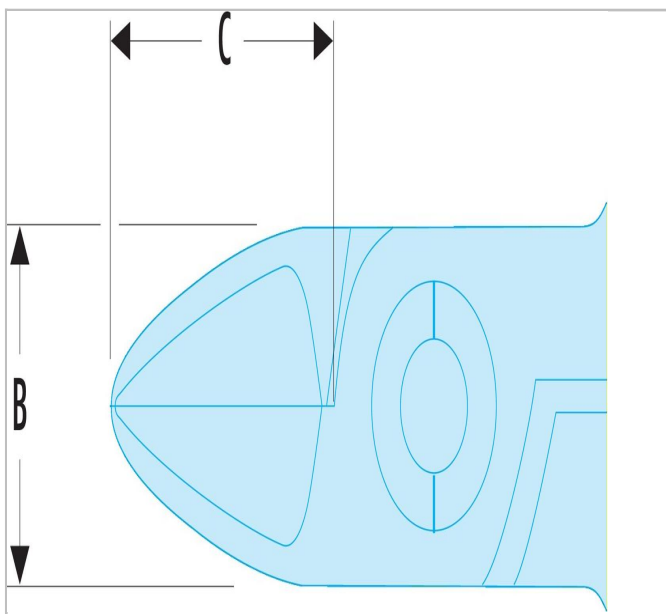

	405.10RMT
Length L [mm]	110.0
Thickness E [mm]	7.0
Head Height C [mm]	11.5
Head Width B [mm]	10.5
Cu - Ni Diameter [mm]	0.3 - 1.2
Cut ["]	h
Fe Wire 30 HRc Diameter [mm]	0.7
Piano Diameter [mm]	0.5
Weight [g]	60.0