



## 405.12MT | Micro-Tech® "high capacity" cutters: power



### Description:

- These pliers are suited to major efforts and repetitive work over a broad range of materials.
- Fall prevention models avoid wire ejection.

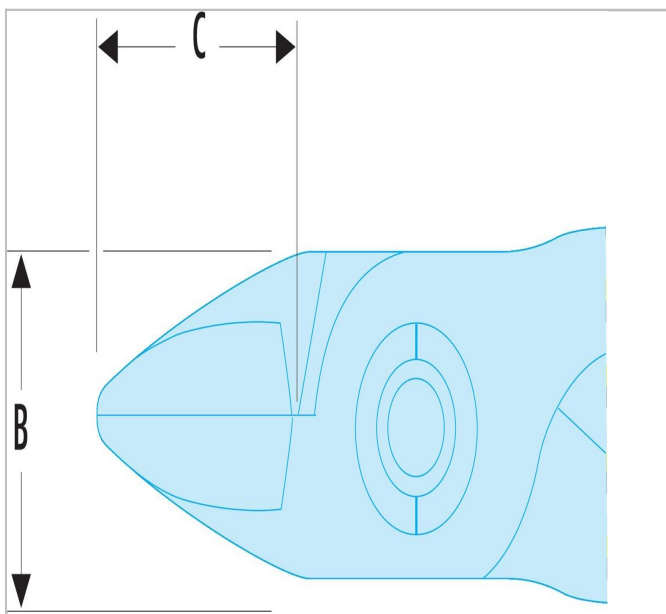

	405.12MT
Length L [mm]	125.0
Thickness E [mm]	8.0
Head Height C [mm]	16.0
Head Width B [mm]	16.0
Cu - Ni Diameter [mm]	0.4 - 2
Cut ["]	h
Fe Wire 30 HRc Diameter [mm]	1.0
Piano Diameter [mm]	0.8
Weight [g]	95.0