

## 416.PMT | Micro-Tech® "thin nose tip" cutters: handling





### Standards:

NF ISO 9654, ISO 9654, DIN ISO 9654, ASME B107.500

### Description:

- These pliers pass under all obstacles of the PCB and provide better visibility.

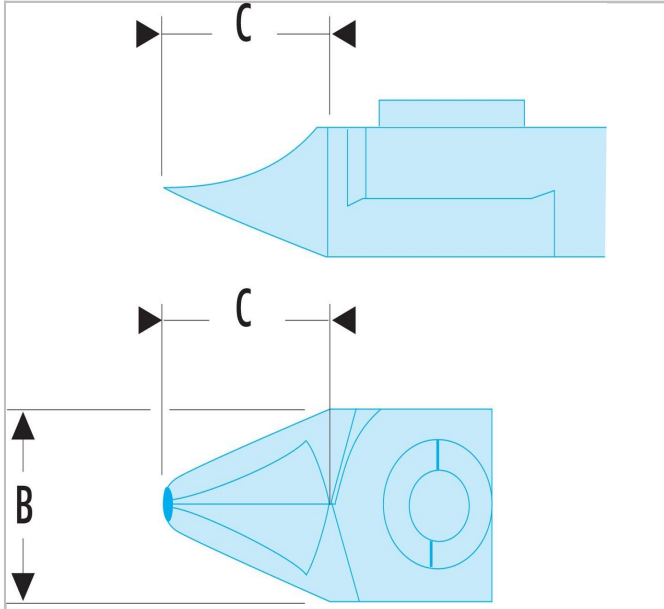

	416.PMT
Length L [mm]	110.0
Thickness E [mm]	7.0
Head Height C [mm]	10.5
Head Width B [mm]	10.5
Head Height C1 [mm]	9.5
Cu - Ni Diameter [mm]	0.1 - 0.8
Cut ["]	H
Fe Wire 30 HRc Diameter [mm]	0.4
Weight [g]	60.0