

44.6X7 | 44 - Metric open end wrenches





Standards:

NF ISO 10102, NF ISO 3318, NF ISO 1711-1, NF ISO 691, ISO 10102, ISO 3318, ISO 1711-1, ISO 691, DIN ISO 1711-1, DIN ISO 691, DIN 3110

Description:

- Open end wrenches = the open ends are slimmer than a standard combination wrench for better thickness accessibility. Examples: brake calipers, hydraulic hose locknuts.
- Heads hinged at 15°.
- Metric sizes: 3.2 to 42 mm.
- Presentation: satin chrome finish.

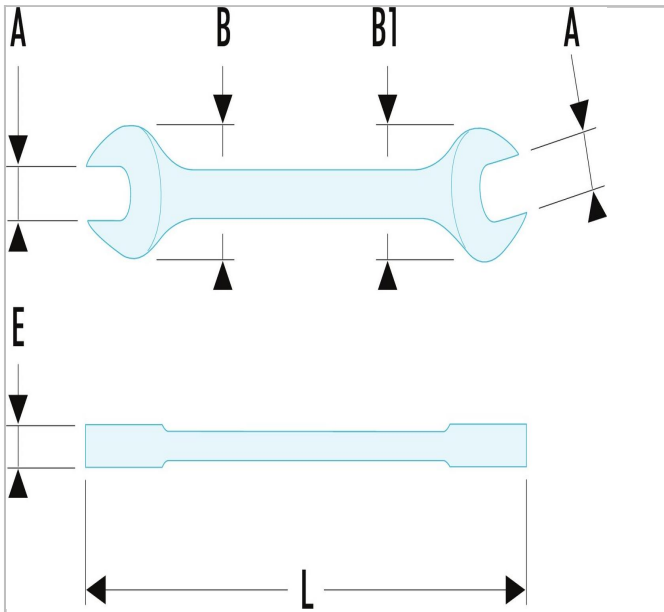

	44.6X7
A [mm]	6x7
Length L [mm]	120.0
Thickness E [mm]	3.7
Head Width B [mm]	15.0
Head Width B1 [mm]	17.5
Weight [Kg]	0.02